



Order Code	TCK-159
Inductance	1 μ H \pm 20% (at 100 kHz / 250 mV)
Impedance (DCR)	22 m Ω max.
Rated Current	5 A max.
Operating Temperature	-55°C to +125°C
RoHS Exemptions	No Exemptions



Impedance Curve

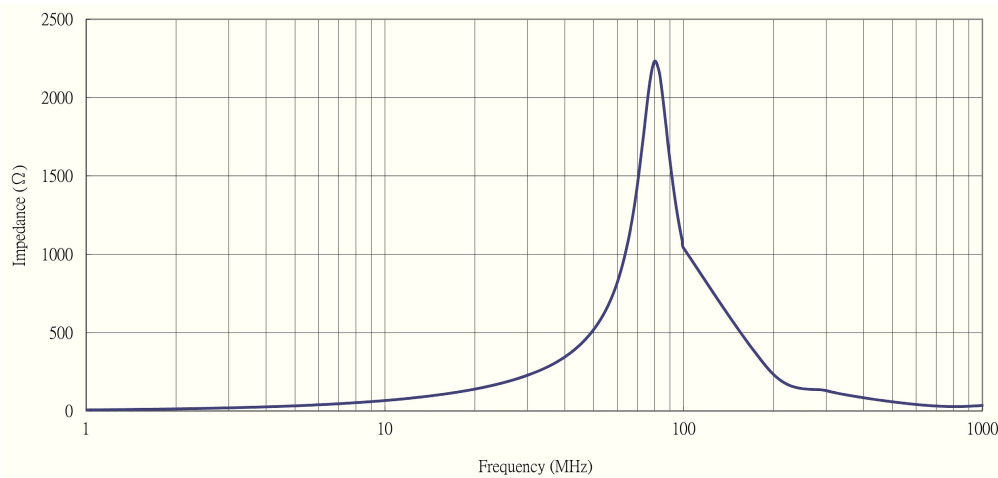

Outline Dimensions

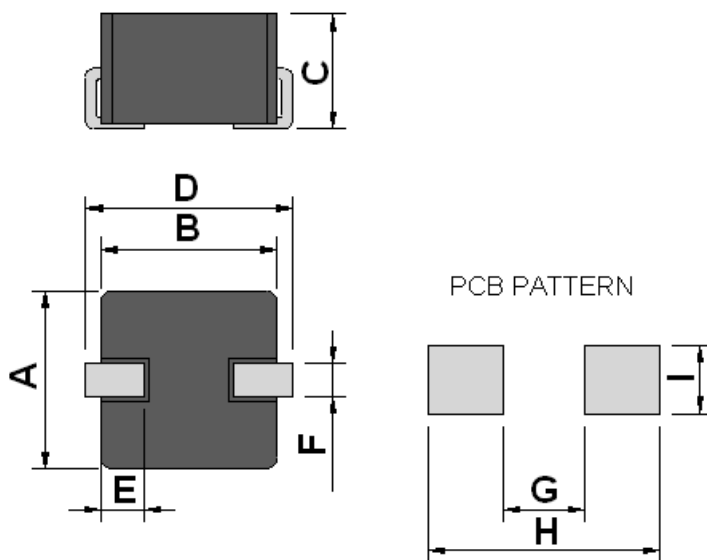

Dimensions [mm]	
A	4.0 \pm 0.3
B	4.0 \pm 0.3
C	2.1 max.
D	4.8 max.
E	1.0 \pm 0.3
F	0.6 \pm 0.1
G	2.2
H	6.0
I	1.5

All specifications valid at +25°C, unless otherwise stated.