




Order Code	TCK-171
Inductance	2.2 μ H \pm 20% (100 kHz / 1 V)
Impedance (DCR)	18 m Ω max.
Rated Current	4.9 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions

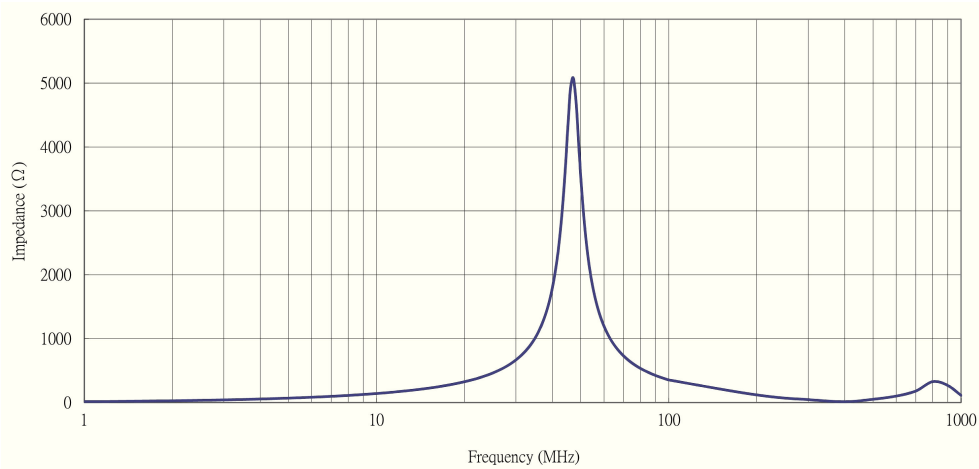

Impedance Curve



Outline Dimensions

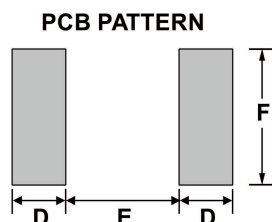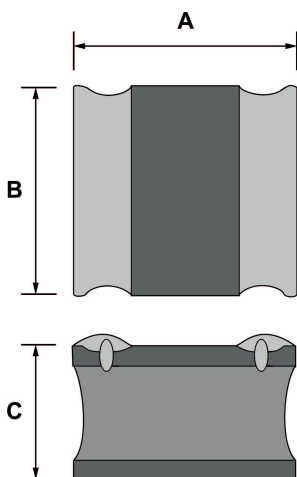

Dimensions [mm]

A	4.9 \pm 0.4
B	4.9 \pm 0.4
C	4.2 max.
D	1.5
E	2.1
F	4.0

All specifications valid at +25°C, unless otherwise stated.