



8-Port CAT5 KVM Switch TK-CAT508 (v1.0R)

- Manage servers over CAT5 cables for distances up to 30 m
- 8 Ethernet ports to connect to servers
- Dual Console support
- Supports both USB and PS/2 connections
- On Screen Display menu controls with password protection
- Requires use of TK-CAT5U or TK-CAT5P units

TRENDnet's 8-Port CAT5 KVM Switch, model TK-CAT508, provides centralized control of SMB server environments. Dual Console support, an On Screen Display, and password protection optimize management efficiency. Requires the use of TRENDnet's TK-CAT5U or TK-CAT5P to connect to a server.

Features



Servers

Manage up to 8 servers over distances of up to 30 meters



Dual Console

Supports the use of two consoles concurrently



VGA Monitor

Designed to connect to a monitor's VGA port



HD

Supports resolutions up to 1600 x 1200 pixels



USB and PS/2 Console Support

Supports both USB and PS/2 console connections



OSD

On Screen Display (OSD) interface for efficient management



Server Ports

The TK-CAT5U supports VGA and USB server ports and the TK-CAT5P supports VGA and PS/2 server ports



Housing

Rugged metal enclosure




Hot Keys

Program Hot Key command shortcuts

Networking Solution



- ① LED indicators
- ② Dual console ports
- ③ Firmware upgrade port

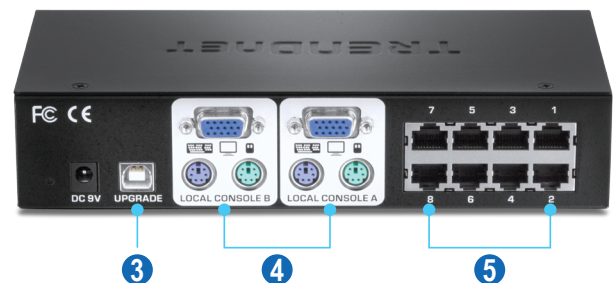

- ④ Dual console ports
- ⑤ Computer ports

Specifications

Dual Console Ports

- Keyboard: USB or PS/2
- Mouse: USB or PS/2
- Monitor: VGA

Computer Ports

- 8 x Fast Ethernet ports
- Requires use of TK-CAT5U or TK-CAT5P to connect to computers

Monitor Resolution

- Max. 1600 x 1200 @ 60 Hz

Switching Control/Management

- OSD (on screen display)
- Keyboard hot key commands
- Notification: sound
- Firmware upgradable (w/ included USB cable)

Scanning Interval

- 10 - 90 seconds

Operating Temperature

- 0 – 40 °C (32 – 104 °F)

Operating Humidity

- Max. 90% non-condensing

Power

- Input: 100 - 240 V AC, 50/60 Hz, 0.4 A
- Output: 9 V DC, 1 A external power adapter
- Consumption: 8.3 Watts Max.

Dimensions

- 205 x 104 x 44 mm (8.07 x 4.1 x 1.7 in.)

Weight

- 748 g (1.65 lbs.)

Warranty

- 2 year limited

Certifications

- CE
- FCC

Package contents

- TK-CAT508
- Quick Installation Guide
- USB cable (1.2 m/4 ft.)
- Power Adapter (9V 1A)

