



Digital Signage Series

Acer DV653bmidv

LFD with media player


The all-new Acer digital signage displays are the best solution to address your customers in a modern way and get the full attention of them.

The DV3 series provides superior pictures with a high amount of dynamic both in still and animated pictures.

It is available in the range of 43" to 98" - for each situation the appropriate display.



- Diagonal size: 165.1 cm (65.0 Zoll)
- Resolution (native): 1,920 x 1,080
- Response time: 8 ms
- Brightness: 450 cd/m²
- Connectivity: VGA, DVI, HDMI

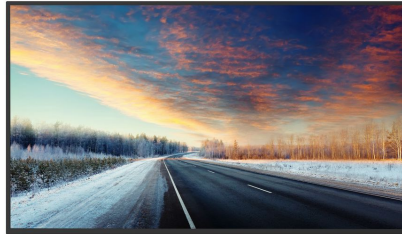

Technical specifications

Diagonal size	165.1 cm (65.0 Zoll)
Active display area (WxH)	1,438 x 809 mm
Resolution (native)	1,920 x 1,080
Aspect ratio	16:9
Pixel pitch (PPI)	0,749 mm (33,9)
Panel type	VA Panel
Response time	8 ms
Brightness	450 cd/m ²
Backlight type	LED
Acer CrystalBrite	No, anti-glare display
Viewing angle (h/v) CR>10:1	178°/178°
Viewing angle (h/v) CR>5:1	178°/178°
Static contrast ratio	4000:1
Dynamic contrast ratio	-
Colors	1.07B
Color space	72% NTSC
Connectivity	VGA, DVI, HDMI
Chassis colour	Black
Frequency (H/V)	60-73kHz / 47-63Hz
Refresh rate (max.)	60 Hz

Dimensions and weight

Dimension (W x H x D)	1,462.0 x 843.30 x 70 mm
Min. thickness without stand	70 mm
Weight (unpacked)	24 kg
Package Dimensions	164 x 98.60 x 22.60 cm
Weight (packed)	33.50 kg
Pallet qty and size (H x W x D)	5 St. (222.0 x 115.0 x 166.0 cm)
Container loading (20'/40')	30 / 70

Others

Storage ambient temperature	Nein
-----------------------------	------

Ordering Information

Model	DV653bmidv
Part number	UM.ND0EE.009
EAN	4713392689871

Power supply and consumption

Power supply	Internal
Min On	tbd W
Max	312 W
Sleep	0.50 W
Off/Standby	0.50 W
Energy Efficiency Class	A
Annual Energy Consumption	184 kWh

ErgoStand

VESA wall mounting	400x400 mm
--------------------	------------

Norms and Standards

MTBF	50,000 h at 25°C
------	------------------