


# suction cup VAS-30-1/8-PUR-B

Part number: 1396090

FESTO

Sealing ring is not included in the scope of delivery.

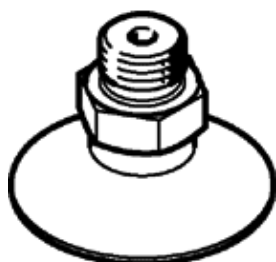

## Data sheet

Feature	Value
Suction cup height compensator	1.9 mm
Nominal size	3 mm
suction cup diameter	30 mm
suction cup volume	1.29 cm <sup>3</sup>
Effective suction diameter	24.8 mm
Position of connection	on top
Assembly position	Any
Suction cup shape	round flat
Operating pressure	-0.95 ... 0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-:]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Ambient temperature	-20 ... 60 °C
Retention force at nominal operating pressure	34 N
Product weight	12 g
Mounting type	Via vacuum port
Vacuum connection	G1/8
Colour	blue
Shore hardness	60 +/- 5
Material of threaded plug	Brass
Materials note	Conforms to RoHS
Material suction cup	PUR