

Tuotetiedot

Tuotekoodi	VG03-0003	Sähkönumero	1912008	EAN-koodi	6410019120080
Tuotenimi	OJL-liitin 280	ETIM-luokka	EC000276		
Johtimet	IN: 1xAl/Cu (35-120mm ²) OUT: 2xCu (6-35 mm ²) / 5xCu (2,5-16mm ²) / 4xCu (2,5-10mm ²)				

Tekniset tiedot


Nimellisvirta (IEC)	Cu	280	A
	Al	250	A
Nimellisjännite (IEC)		1000	V
		-	
		-	
Napaluku		1	kpl
Max. Johdinkoko		120	mm ²
Kiristysmomentti			
	95-120 mm ²	19	Nm
	50-70 mm ²	10	Nm
	25-35 mm ²	6	Nm
	2,5-16 mm ²	3	Nm
Input	1xAl/Cu (35-120mm²)		
Output	2xCu (6-35 mm²) / 5xCu (2,5-16mm²) / 4xCu (2,5-10mm²)		



Käyttölämpötila	80	°C
Paino	178	g
IP-suojaus	IP20	
Standardit	EN 61238-1:2003; EN 60947-7-1:2009	
Väri / Materiaali	Harmaa kansi, Harmaa kotelo RAL 7035 PA66/V0, Runko tinapinnoitettua alumiinia	
Kiinnitys / KytKentä	DIN-kiskokiinnitys ja 2x ruuvikiinnitys (M5)	


Kuvaus

1-napainen OJL-liitin on tarkoitettu sähkölaitteiden haaroituskytkentöihin. Liittimessä 1 syöttöjohdin- ja 11 haaroitusjohdinaukkoa. Liitinkotelo on tinapinnoitettua alumiinia.

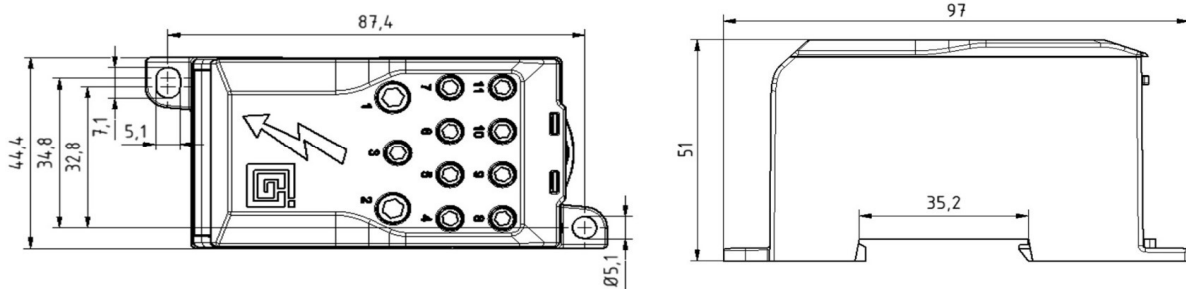Mittakuva

Pakkaus

Pakkausmuoto	Laatikko	Kpl / Pakkaus	12	Paino [kg]	2,30
Pituus [mm]	210	Leveys [mm]	155	Korkeus [mm]	105

Ouneva Oy

Teollisuustie 21
 FI-82730 Tuupovaara
 Finland

Tel. +358 400 179 750
info@ouneva.fi

www.ounevagroup.fi
www.ounevaproducs.fi

Product data

Product code	VG03-0003	STK-code	1912008	EAN-code	6410019120080
Product name	OJL-connector 280			ETIM class	EC000276
Wires	IN: 1xAl/Cu (35-120mm²) OUT: 2xCu (6-35 mm²) / 5xCu (2,5-16mm²) / 4xCu (2,5-10mm²)				

Technical data

Nominal current (IEC)	Cu	280	A
	Al	250	A
Nominal voltage (IEC)		1000	V
		-	
		-	
Number of poles		1	pcs
Max. Cross section		120	mm ²
Tightening torque			
	95-120 mm ²	19	Nm
	50-70 mm ²	10	Nm
	25-35 mm ²	6	Nm
	50-70 mm ²	3	Nm

Input	1xAl/Cu (35-120mm²)
Output	2xCu (6-35 mm²) / 5xCu (2,5-16mm²) / 4xCu (2,5-10mm²)
	-

Operating temperature	80	°C
Weight	178	g
IP-protection	IP20	


Standards	EN 61238-1:2003; EN 60947-7-1:2009
Color / Material	Grey Cover, Grey Housing RAL 7035 PA66/V0, Connector part tin plated aluminium
Mounting / Connection	DIN-rail and 2x screw (M5) mounting



Description

Single pole distribution block for branching connections. The OJL distribution block is compact and distributes the current through 11 output cables.

Drawing

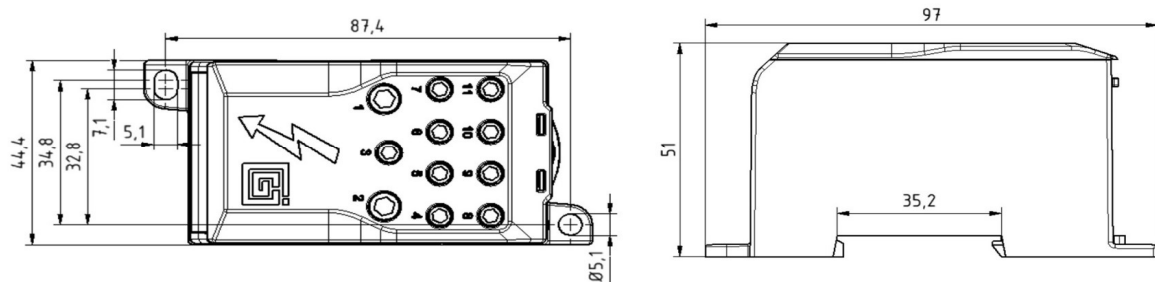

Package

Package	Box	Pcs / Package	12	Weight [kg]	2,30
Length [mm]	210	Width [mm]	155	Height [mm]	105

Ouneva Oy

Teollisuustie 21
FI-82730 Tuupovaara
Finland

Tel. +358 400 179 750
info@ouneva.fi

www.ounevagroup.fi
www.ounevaproducts.fi