

Product data

Product code	VG03-0059	STK-code	1914376	EAN-code	6430051861758
Product name	OJL connector 80	ETIM class	EC000276		
Wires	IN 2x(Al/Cu) 2,5-16 mm ² OUT: 6x (Cu) 2,5-6mm ²				

Technical data


Nominal current (IEC)	Cu	80	A
	Al	75	A
Nominal voltage (IEC)	1000 V AC / 1500 V DC		V
	-		
	-		
Number of poles	1		pcs
Max. Cross section	16		mm ²
Tightening torque			
	2,5-6 mm ²	1	Nm
	10-16 mm ²	6	Nm
	-		
	-		
Input	2x Al/Cu 2,5-16 mm²		
Output	6x Cu 2,5-6 mm²		
	-		
Operating temperature	80		°C
Weight	38		g
IP-protection	IP20		
Standards	EN IEC 61238-1:2019; EN 60947-7-1:2009		
Color / Material	Black Cover PC, Grey Housing RAL 7035 PA66/V0, Connector part tin plated aluminium		
Mounting / Connection	Din rail mounting		



Description

The single pole distribution block for branching connection. Distribution block with 2 inputs and it will distribute the current through 6 output cables. Connector is made from tin plated aluminium and housing is PA66 V0.

Drawing

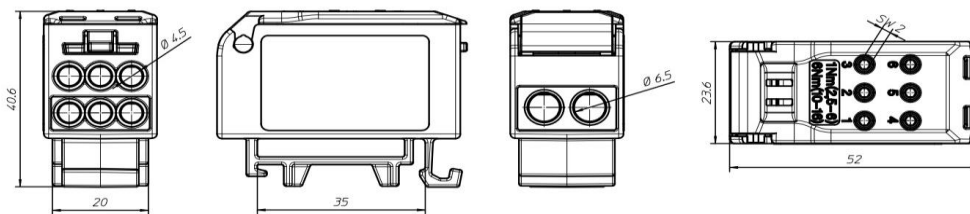

Package

Package	Box	Pcs / Package	33	Weight [kg]	1,40
Length [mm]	210	Width [mm]	155	Height [mm]	105

Ouneva Oy

Teollisuustie 21
FI-82730 Tuupovaara
Finland

Tel. +358 400 179 750
info@ouneva.fi

www.ounevagroup.fi
www.ouneva.fi