


VALUE 19" PDU for Cabinets 7x 2300W, CEE 7/4 M German Type, 1.8 m

Product No.	19.99.1633
Manufacturer	VALUE
Manufacturer No.	19.99.1633
EAN (single piece)	7630049627000

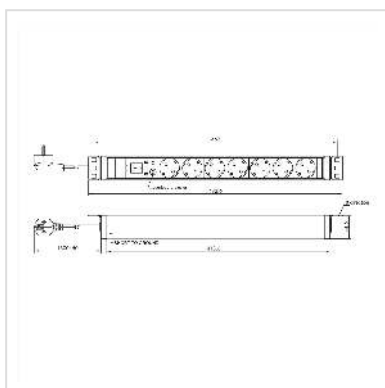

19" PDU with 7x German Type socket and supply cable (1.8m) with German Type plug, 1U, for installation in 19" cabinets, incl. installation angle.

- 19" socket strip (1 U) for installation in 19" cabinets, incl. mounting brackets
- With overload protection
- 7 German Type sockets (CEE 7/4)
- Arrangement of sockets: 45°.
- Anodised aluminium profile
- Cable type: 1.8m H05VV-F 3G 1.5mm², black
- Maximum load/power: 16A 3500W
- Colour: ALU / black RAL 9005
- Width: 440mm

Technical specifications

Manufacturer	VALUE
Product group	Power Bars
Product type	19" power strip
Colour	black
Length	1.8 m
Function	19" PDU for Cabinets
Mounting form	19" Rackmount

Max. capacitance	3500W
Max. voltage	250V AC
ON/OFF Switch	Yes
Quantity of outputs/angles	7 / 45°
Output alignment	Line
Dimensions (HxWxD)	44 x 440 x 44 mm
Material (casing)	Aluminium
Colour (Design profile)	RAL 9005 black
Connection cable	H05VV-F 3G 1,5mm ²
Connector plug	CEE 7/4 German Type
Mains connection	Protective contact plug
Height of packaging (single piece)	60 mm
Width of packaging (single piece)	100 mm
Depth of packaging (single piece)	500 mm
Package weight (single piece)	0.87 kg