




[PRODUCT OVERVIEW](#) [ELECTRONIC COMPONENTS](#) [PASSIVE COMPONENTS](#) [RESISTIVE COMPONENTS](#) [CARBON POTENTIOMETERS](#) [CARBON POTENTIOMETERS LIN MONO / NO SWITCH \(AM-series\)](#)

## POTMETER MONO LIN 2K2

**K002AM**

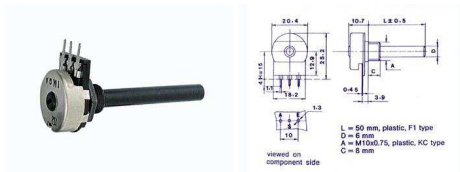

20mm rotary carbon track potentiometers for PCB mounting. Metal/plastic housing and plastic axle ( $\varnothing$  6mm). Optional single-pole switch (1A-24Vdc / 0.3A-250Vac).

### Features

- linear (A-series)
- mono
- no switch
- OMEG

### Specifications

- resistance range: 100E to 4M7 (E3-series)
- max. power dissipation: 0.4 W
- tolerance:  $\pm 20\%$
- max. working voltage: 500 VDC
- temperature range:  $-10^{\circ}\text{C}$  to  $+70^{\circ}\text{C}$
- electrical rotation:  $300^{\circ} \pm 5^{\circ}$