


PFW 6800 Display Wall Mount fixed

The PFW 6800 is a sturdy and at the same time elegant fixed wall mount. It features an aesthetically integrated lock whilst maintaining a depth of only 35 mm. The mount can hold displays from 55 to 80 inch, weighing up to 100 kg. The integrated touch-screen stabiliser ensures that even the largest touch screens can be mounted perfectly vertical and stable on the wall.



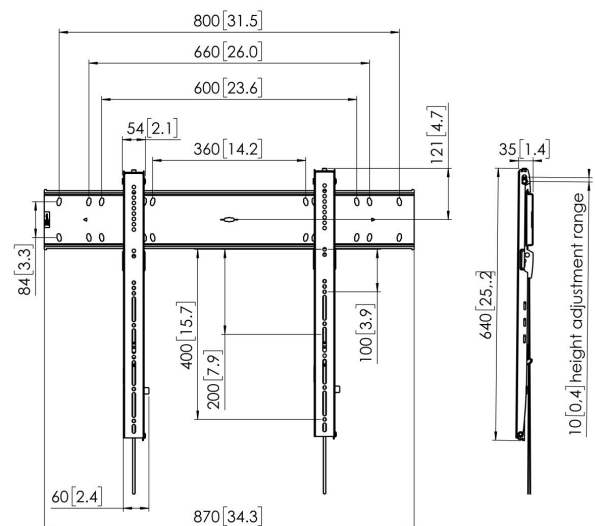

PFW 6800 Display Wall Mount fixed

Specifications

Article number (SKU)	7368000
Colour	Black
EAN single box	8712285334160
Product size	L
TÜV certified	Yes
Guarantee	5 years
Min. screen size (inch)	55
Max. screen size (inch)	80
Max. weight load (kg)	100
Min. hole pattern	75mm x 75mm
Max. hole pattern	800mm x 400mm
Max. bolt size	M8
Max. height of interface (mm)	636
Max. width of interface (mm)	870
Fischer inside	Yes
Levelling function	Post-installation horizontal levelling
Lock options	Lock included / integrated
Max. horizontal hole pattern (mm)	800
Max. screen size (inch)	80
Max. vertical hole pattern (mm)	400
Min. distance to the wall (mm)	35
Min. horizontal hole pattern (mm)	75
Min. screen size (inch)	55
Min. vertical hole pattern (mm)	75
Orientation	Landscape
Service position	Yes
Universal or fixed hole pattern	Universal

VOGEL'S HOLDING BV (©)

All rights reserved.
Subject to printing errors,
technical and price
amendments.

Date: 2022-06-02



Vogel's. For Sure.