




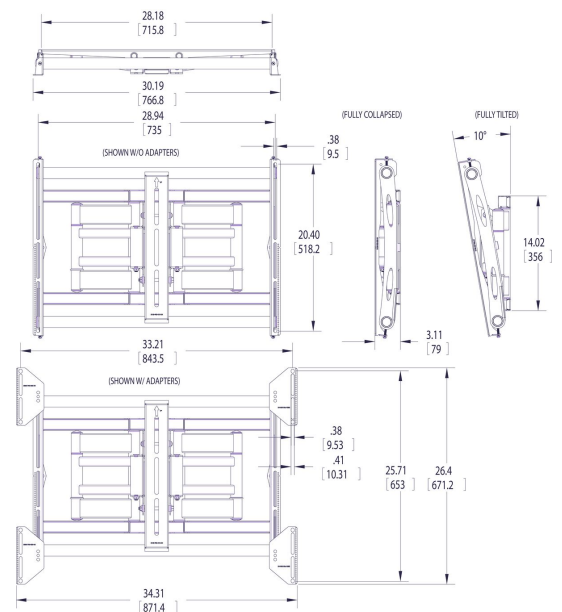

PFW 6851 Display Wall Mount turn & tilt

The PFW 6851 is a swingout mount for displays up to 80 kg / 175 lbs. Typically fits displays ranging from 42 - 85 inch or displays with a mounting pattern of 200 x 200 mm to 800 x 600 mm.

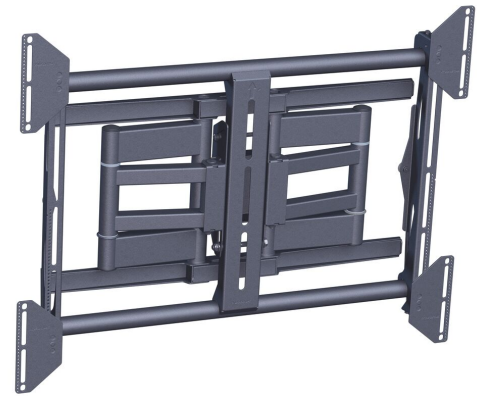

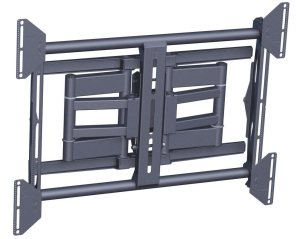

PFW 6851 Display Wall Mount turn & tilt

Specifications

Article number (SKU)	7368510
Colour	Black
EAN single box	8712285323386
Product size	L
TÜV certified	Yes
Tilt	Tilt up to 10°
Turn	Up to 90°
Guarantee	5 years
Min. screen size (inch)	42
Max. screen size (inch)	85
Max. weight load (kg)	80
Max. height of interface (mm)	671
Max. width of interface (mm)	871
Levelling function	Post-installation horizontal levelling
Lock options	No lock
Max. distance to the wall (mm)	404
Max. horizontal hole pattern (mm)	800
Max. screen size (inch)	85
Max. vertical hole pattern (mm)	600
Min. distance to the wall (mm)	79
Min. screen size (inch)	42
Number of pivot points	3
Orientation	Landscape

VOGEL'S HOLDING BV (©)

All rights reserved.
Subject to printing errors,
technical and price
amendments.

Date: 2022-06-02



Vogel's. For Sure.