

WXD 2020 SOLD./DESOLD. STAT. 230V UK

2-Channel Solder- and Desoldering Station, 200 W (255 W)
Product no.: T0053429399N



Benefits




For this purpose, we recommend:



Solder fume extractors



Soldering irons

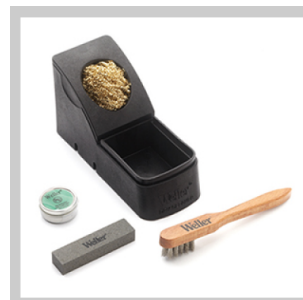

Cleaning




Pre-heating plates



Technical Data

Dimensions L x W x H (mm)	174 x 154 x 135
Dimensions L x W x H (inches)	6, 69 x 5, 94 x 5, 12
Weight (approx.) in kg	3.8
Voltage	230 V
Power	200 W (255 W)
Channels	2
Temperature range (depends on tool) °C	---
Temperature range (depends on tool) °F	---
Temperature accuracy °C	±9
Temperature accuracy °F	±17
Temperature stability °C	±2
Temperature stability °F	±4
Equipotential bonding socket	Via 3,5 mm pawl socket on back of unit.
Display	255 x 128 dots / Backlighting
Air consumption l/min	35
Operating pressure in bar/psi	4,0 - 6,0 / 58 - 87
Capacity l/min	---
Vacuum	max. 55 kPA (8psi)

Owning the bench

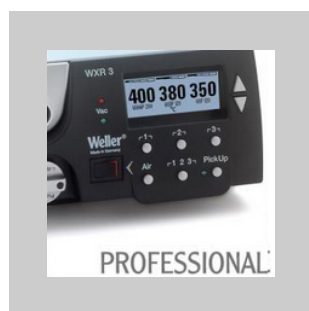

PROFESSIONAL



FILTRATION



EREM



XCELITE