

WX 2021 SOLD STA WXMP/WXMT 230V UK F/G




Benefits




For this purpose, we recommend:



Solder fume extractors

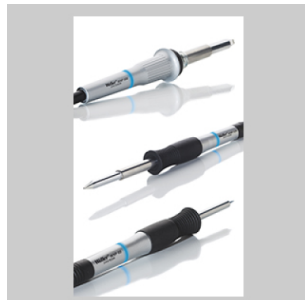

Soldering irons

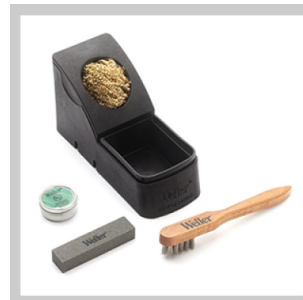

Cleaning



Pre-heating plates



Technical Data

| | |
|--|--|
| Dimensions L x W x H (mm) | 174 x 154 x 135 |
| Dimensions L x W x H (inches) | 6,85 x 6,06 x 5,31 |
| Weight (approx.) in kg | 3.45 |
| Voltage | 230 V |
| Power | 200 W (255 W) |
| Channels | 2 |
| Temperature range (depends on tool) °C | 100 - 550 |
| Temperature range (depends on tool) °F | 200 - 999 |
| Temperature accuracy °C | ±9 |
| Temperature accuracy °F | ±17 |
| Temperature stability °C | ±2 |
| Temperature stability °F | ±4 |
| Equipotential bonding socket | Via 3,5 mm pawl socket on back of device |
| Display | 255 x 128 dots / Backlighting |
| Air consumption l/min | --- |
| Operating pressure in bar/psi | --- |
| Capacity l/min | --- |
| Vacuum | --- |

Owning the bench



PROFESSIONAL



FILTRATION



EREM



XCELITE