


EvoSIGNAL / EvoSIGNAL Accessories

## Midi Bracket Cable Gland WM GY

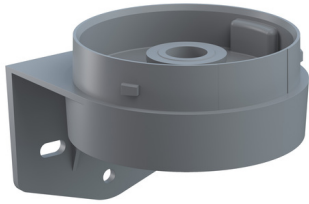

Part No.: 261.700.06

RoHS


### MECHANICAL DATA

Length	93 mm
Width	85 mm
Height	75 mm
Materials	PC/ABS
Housing colour	Grey
Protection category	IP66
Cable entry	Screwed cable gland
Cable entry minimum	d = 8 mm
Cable entry maximum	d = 12 mm
Tension relief	Present (conforms to VDI)
Type of fixing	Wall mounting
Working temperature minimum	-30°C
Working temperature maximum	+60°C
Weight with packaging	87 g
Product weight	87 g

### ELECTRICAL DATA

Pollution degree	3
------------------	---

### DRAWING

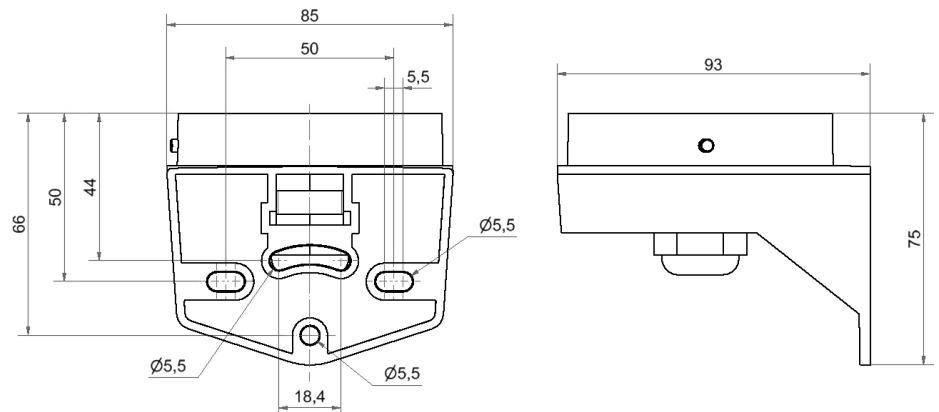

For additional installation and mounting information, refer to the appropriate user guide at [www.werma.com](http://www.werma.com). This printed copy is for information only and is subject to alteration.