

Brush module for Euro faceplates



Aperture brush modules for Euro faceplates XBR(wh/bk) XBR(wh/bk)G2

TUK's brush modules easily convert standard Euro faceplates into popular brush faceplates, providing a tidy exit for cables exiting a wall or trunking. They simply snap-in to single gang (86x86mm) or twin gang (86x146mm) faceplates and are available in white or black.

Features:

- Suitable for installers or faceplate manufacturers
- Snap easily into place
- Suitable for 50x50mm or 50x100mm openings in Euro single gang (86x86mm) or twin gang (86x146mm) faceplates
- Available in individual poly bags or in bulk packs of 50.

Specifications:

- Net weight (including primary packaging): XBRwh/bk - 10g, XBRwh/bkG2 - 18g
- Dimensions (including primary packaging): XBRwh/bk 55x55x13mm, XBRwh/bkG2 55x105x13mm
- Colour: Black or White

Materials: ABS UL94V0 Flame Retardant plastic frame with Nylon brush.

Packaging: Individual poly bags then in 20's or in bulk packs of 50

Commodity code: 85177090

EAN:

Singly packed:

XBRwh 5055386510747

XBRbk 5055386510754

XBRwhG2 5055386510761

XBRbkG2 5055386510778

Packed in 50's:

XBRwh#50 5055386510785

XBRbk#50 5055386510792

XBRwhG2#50 5055386510815

XBRbkG2#50 5055386510808

Country of Origin China



Aperture brush modules for Euro faceplates XBR(wh/bk) XBR(wh/bk)G2 back view






Illustrative Image

ROHS Compliant

Code: XBr*


*= bk or wh

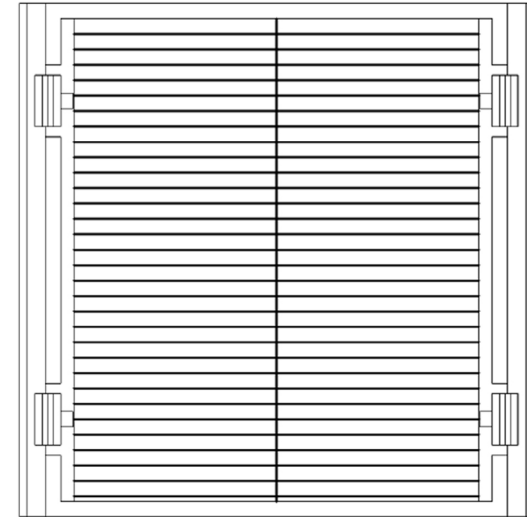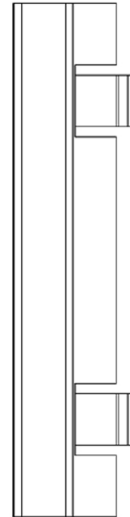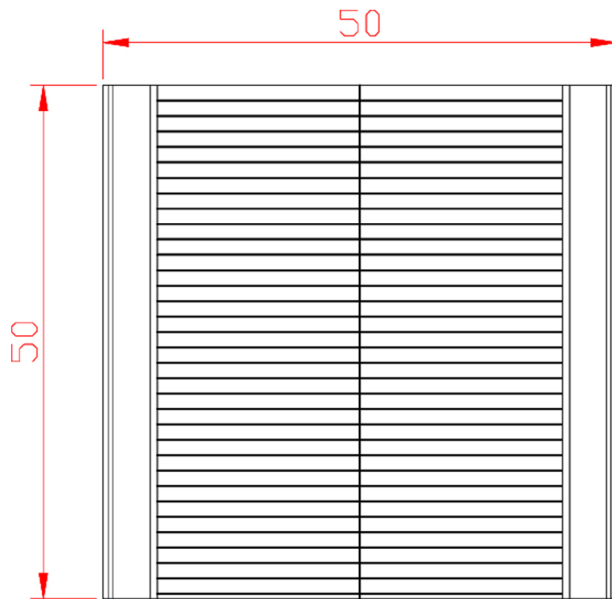

Material ABS



Tolerance

0.00-20.00	±0.10
20.00-50.00	±0.15
50.00-100.00	±0.20
100.00-	±0.25
Angle	±30°

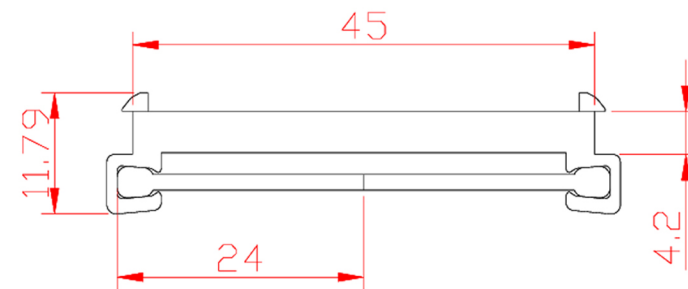

ROHS Compliant

Code: XBr*G2
***= bk or wh**

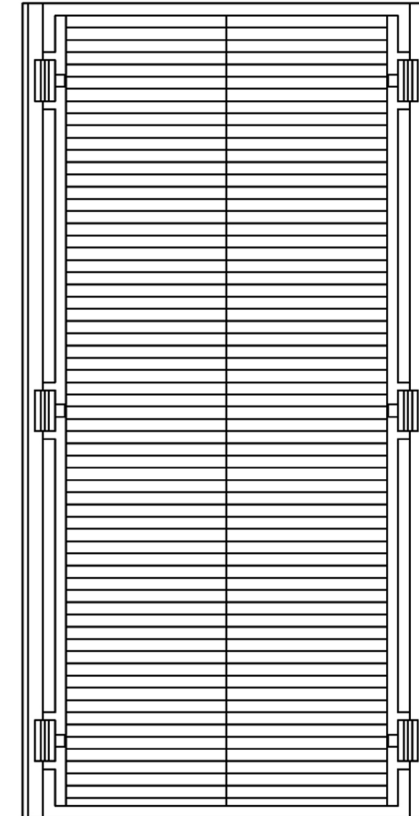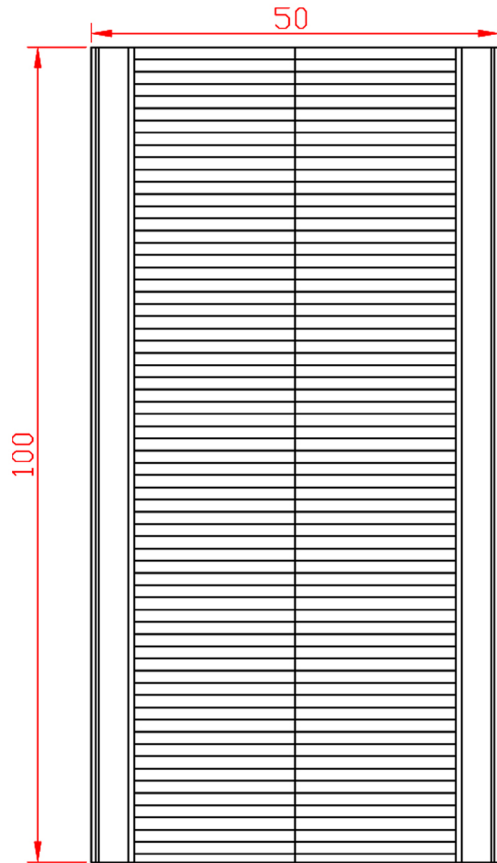

Material ABS

Tolerance

0.00-20.00	±0.10
20.00-50.00	±0.15
50.00-100.00	±0.20
100.00-	±0.25
Angle	±30°

