


## Socket XK-410

In-line, rigid, Ø 4 mm, accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve, for self-assembly of test leads.

**Screw connection.**

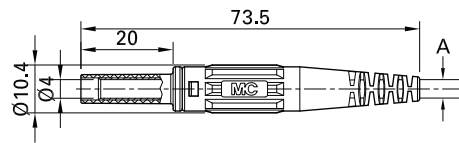

Order No.	Type	Rated voltage/current	Cable (A)			*Standard colors
66.9155-*	XK-410	1000 V, CAT II / 32 A 600 V, CAT III / 32 A	max. Ø 3.9 mm	max. 2.5 mm <sup>2</sup>	Ni	21 22 23 24 25



Optional colors 20 26 29

Further information, page 6



**Assembly instructions MAH548**

[www.staubli.com/electrical](http://www.staubli.com/electrical)