


## Xmore® SSD 2,5" SATA III

### Product description



<b>Xmore® Partnumber</b>	SSD120GXACTT-023Z	SSD002TXACTT-023Z
	SSD240GXACTT-023Z	SSD004TXACTT-022Z
	SSD480GXACTT-023Z	SSD008TXACTT-022Z
	SSD960GXACTT-023Z	
<b>Flash Type</b>	Kioxia BiCS 5 3D TLC	
<b>Capacity</b>	120 GB up to 8 TB	
<b>SATA Interface</b>	SATA Revision 3.0 SATA 1.5Gbps, 3Gbps, and 6Gbps	
<b>Power Consumption</b>	Active mode: Idle mode: DEVSPLP mode	
<b>Performance Sequential *960GB</b>	Read: Write:	Up to 550 MB/s Up to 490 MB/s
<b>Advance Flash Management</b>	Static and Dynamic Wear-Leveling Bad-Block Management TRIM // S.M.A.R.T Over-Provision LDPC ECC Engine Read-Refresh Algorithmen	
<b>TBW (Terabytes Written)</b>	4388 TBW for 960GB	
<b>Temperature Range</b>	Storage: Operation:	-40°C to 85°C 0°C to 70°C
<b>RoHS compliant</b>		

## Technical draw

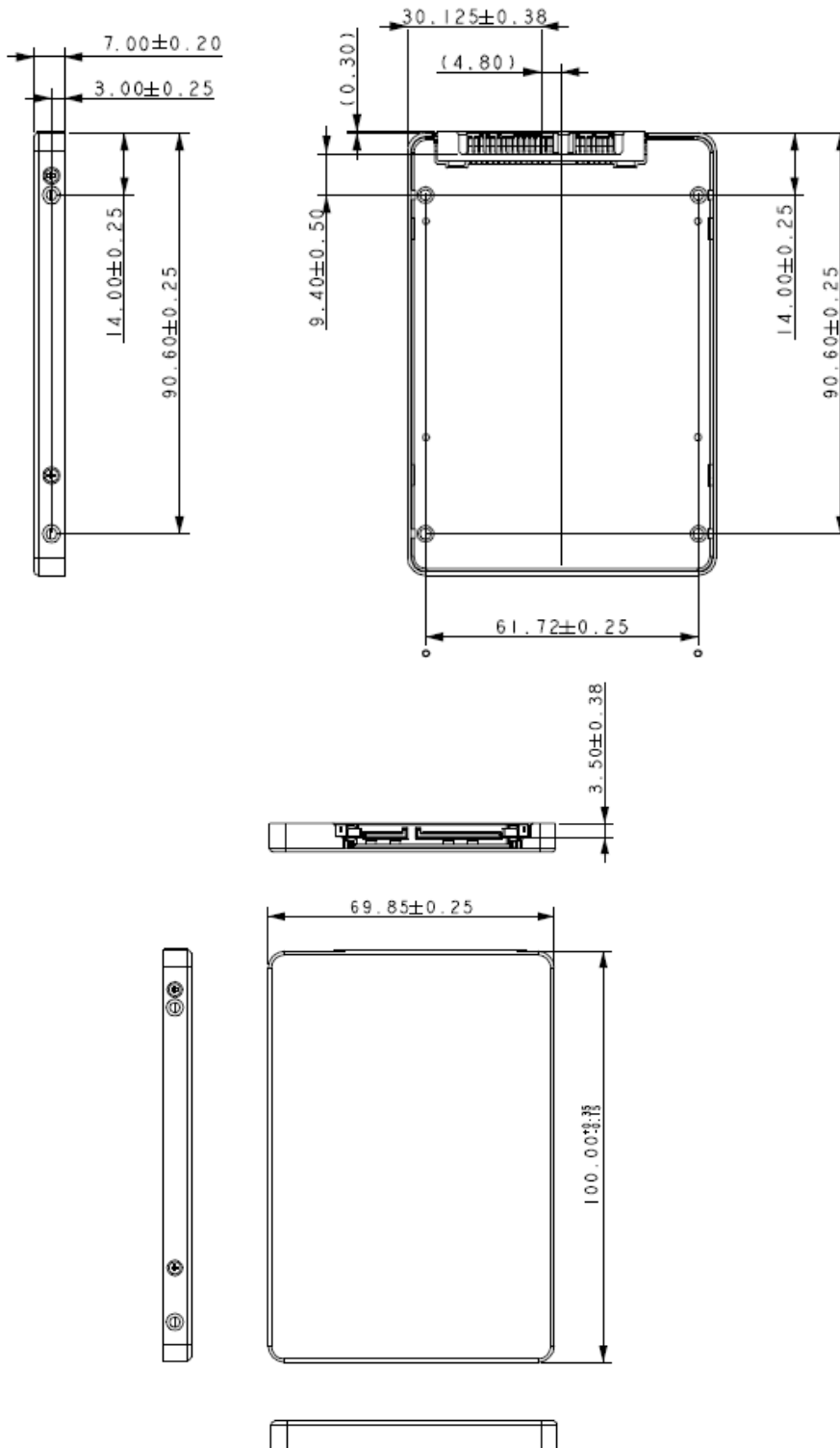

Note: Xmore® reserves the right to change non BoM parts without notice.