




KELVIN CLIPS

Kelvin Clips

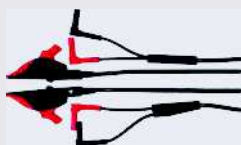

Kelvin Clip



Kelvin Probe



Kelvin Clip & Probe

Kelvin clips are used for connecting low impedance resistors (e.g. contact resistors, shunts etc.) to an ohmmeter with 4-wire connection. This allows for compensation of cable resistance.

- KC4: Kelvin clips (1 set = 2 pieces) for 4-pole connection of low-resistance DUTs, cable length: 120 cm, clip for connection to DUTs with diameters of up to 30 mm
- KC27: Kelvin probes (1 set of 2 ea.) with 2 stainless steel tips for 4-pole connection of low-resistance DUTs, 120 cm cable length

KC&S: SET INCLUDING 1 KELVIN CLIP AND 1 KELVIN PROBE

- Cable set including 1 Kelvin clip and 1 Kelvin probe, as well as 2 stainless steel tips for 4-wire measurement, 120 cm cable length with 4 mm angle plugs

Type	Article
KC4	Z227A
KC27	Z227B
KC&S	Z227C

ACCESSORIES

Multimeters Overview

Type	METRAHIT																METRALINE DMM15	METRALINE DMM16	METRAmax							
	BASE/EBASE	TECH/ETECH	X-TRA/EXTRA	SECULIFE HIT	PRO/ESPECIAL	OUTDOOR	T-COM/plus	ISO/ISO@Aero/COIL	ENERGY	ULTRA	METRACAL MC	CAL	2 plus	WORLD	30M	27M/I			27H+E CAR	1A/2A	2	3	6	12	40S	3A
High-Frequency Probe																										
Z3431-2	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
Measuring Accessories																										
KS17-ONE	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
KS17-2	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
KS17-S	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
KS-AP	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
KS-NTS	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
KS21-T	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
KS29	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
KY95-3	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
Z502U	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
Kelvin Clips																										
KC4	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
KC27	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
KC&S	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-

FUSES

Overview

Type	Designation	Article	For following devices:
FF (UR) 16 A / 1 kV AC/DC	Fuse link	Z109B	METRAHIT 24S ... 26S
FF (UR) 10 A / 1 kV AC/DC	Fuse link	Z109L	METRAHIT PRO, TECH, X-TRA, ETECH, EXTRA, ISO (AERO), OUTDOOR, 2, WORLD, ULTRA, 29S, ENERGY
FF (UR) 1.6 A / 1 kV AC/DC	Fuse link	Z109C	METRAHIT 23S ... 26S, 27M/I, 27H+E CAR, 29S
FF 1.6 A / 700V AC	Fuse link	Z109E	METRAHIT ONE Plus/2/WORLD/2A, T-COM (PLUS), METRAmax 12, METRAport 3A
FF (UR) 16 A / 600V AC	Fuse link	Z109D	METRAHIT ONE Plus
FF 630 mA / 700V	Fuse link	Z109J	METRAHIT CAL, METRAHIT 1A
FF 6.3 A / 400V	Fuse link	Z109K	METRAHIT 1A
FF 16 A / 600V AC	Fuse link	Z109A	METRAmax 12, METRAport 3A, METRAHIT 2A
FF 1 A / 380V (5 x 20)	Fuse link	Z109H	METRAport 32S / 32XS
T 16 A / 500V (6.3 x 32)	Fuse link	Z109I	METRAport 32S / 32XS
FF 0.63 A / 400V	Fuse link	Z109M	METRACAL MC