

7506ULT

ULTRA LIFE | Signal lamps for cars and motorcycles



Product benefits

- An ideal daytime running lamp due to long life span
- Up to triple the lifetime (compared to standard lamps)



Product datasheet

Technical data

 

Electrical data

Power input	25 W
Nominal voltage	12.0 V
Nominal wattage	21.00 W
Power input tolerance	±6 %
Test voltage	13.5 V

Photometrical data

Luminous flux	460 lm
Luminous flux tolerance	±15 %

Dimensions & weight

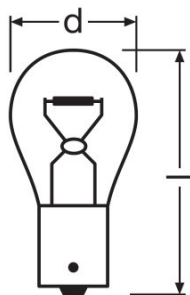

Length	52.5 mm
Diameter	25.0 mm
Product weight	7.88 g

Lifespan

Lifespan B3	500 h
Lifespan Tc	1000 h

Additional product data

Base (standard designation)	BA15s
-----------------------------	-------

Certificates & standards

ECE category	P21W
Approval marks – approval	E1 approval

Product datasheet

Country specific categorizations

Order reference	7506ULT
------------------------	---------

Country specific information

Product code	METEL code	SEG-No.	STK-Number	UK Org
4008321415349	OSRA7506ULT	-	-	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4008321415141	7506ULT	Blister 2	93 mm x 35 mm x 49 mm	0.16 dm ³	23.00 g
4008321415158	7506ULT	Shipping carton box 20	279 mm x - x 116 mm	4.69 dm ³	340.00 g
4008321415349	7506ULT	Unpacked 1	24 mm x 18 mm x 19 mm	0.01 dm ³	4.00 g
4008321415356	7506ULT	Folding carton box 10	58 mm x 54 mm x 139 mm	0.44 dm ³	100.80 g
4008321415363	7506ULT	Shipping carton box 50	273 mm x - x 65 mm	2.57 dm ³	554.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.