

► QCS SERIES

- Fiber glass enforced polyamide body
- Durable and strong, Power Lever to give extra pressure
- Removable pads, with V-groove
- Easy access release mechanism
- Comfortable handle from ALL angles, you can use upside down, front to back



Superior™

Power Lever System

Ref. nr	Clamping	Depth		Spare Pads Available	V Groove Pads	Power lever	Clamping Force	EAN Code
QCS-150	150 mm	95 mm	6	Yes	Yes	Yes	300 Kg	7314150135998
QCS-300	300 mm	95 mm	6	Yes	Yes	Yes	300 Kg	7314150136001

► QCB SERIES

- Variable speed mechanism, which makes it easier to reach high clamping force
- Removable pads, with V-groove
- Easy to turn in to a spreader with the Spreader button
- Easy access release mechanism
- Comfortable handle from ALL angles, you can use upside down, front to back



Ref. nr	Clamping	Depth		Spare Pads Available	V Groove Pads	Power lever	Clamping Force	EAN Code
QCB-150	150 mm	95 mm	6	Yes	Yes	No	200 Kg	7314150135912
QCB-150-6P	150 mm	95 mm	6				200 Kg	7314150135929
QCB-300	300 mm	95 mm	6	Yes	Yes	No	200 Kg	7314150135936
QCB-300-6P	300 mm	95 mm	6				200 Kg	7314150135943
QCB-450	450 mm	95 mm	6	Yes	Yes	No	200 Kg	7314150135950
QCB-600	600 mm	95 mm	4	Yes	Yes	No	200 Kg	7314150135967
QCB-900	900 mm	95 mm	4	Yes	Yes	No	200 Kg	7314150135974
QCB-1250	1250 mm	95 mm	4	Yes	Yes	No	200 Kg	7314150135981

► QCG SERIES

- Easy access in more confined spaces thanks to the smaller body
- Easy to turn in to a spreader with the Spreader button
- Easy access release mechanism
- Comfortable handle from ALL angles, you can use upside down, front to back



Ref. nr	Clamping	Depth		Spare Pads Available	V Groove Pads	Power lever	Clamping Force	EAN Code
QCG-150	150 mm	70 mm	6	No	Yes	No	125 Kg	7314150135899
QCG-300	300 mm	70 mm	6	No	Yes	No	125 Kg	7314150135905

► QC-PAD REPLACEMENT SPARE PADS - MEDIUM & SOFT

Ref. nr	Description		EAN Code
QC-PAD-M	MEDIUM	10	7314150136025
QC-PAD-S	SOFT	10	7314150136032




► SPRING CLAMPS

Ref. nr	Clamping		EAN Code
420SC-25	25 mm	10	7314150169825
420SC-50	50 mm	5	7314150169832



► 420 SCREW CLAMP

Ref. nr	Length	Depth		EAN Code
420-50-100	100 mm	50 mm	5	7311518011253
420-50-200	200 mm	50 mm	5	7311518011253
420-60-120	120 mm	60 mm	5	7311518011253
420-60-300	300 mm	60 mm	5	7311518043834
420-80-160	160 mm	80 mm	5	7311518011161
420-100-200	200 mm	100 mm	5	7311518011178
420-120-250	250 mm	120 mm	5	7311518011185
420-120-300	300 mm	120 mm	5	7311518011277
420-120-400	400 mm	120 mm	1	7311518011284
420-120-500	500 mm	120 mm	1	7311518011192
420-120-600	600 mm	120 mm	1	7311518011215
420-120-800	800 mm	120 mm	1	7311518011291
420-120-1000	1000 mm	120 mm	1	7311518127398
420-120-1250	1250 mm	120 mm	1	7311518035235
420-120-1500	1500 mm	120 mm	1	7311518035242
420-140-400	400 mm	140 mm	1	7311518043841
420-175-400	400 mm	175 mm	1	7311518011222

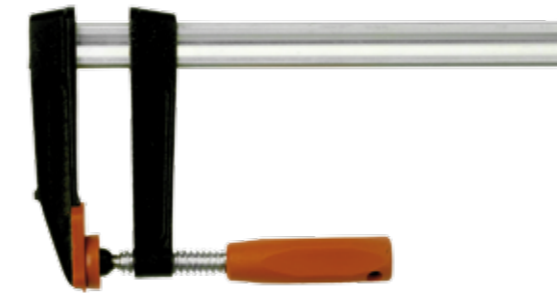

IND-0536-INT

SNAEurope

BAHCO QUICKCLAMPS
MADE FOR PRESSURE - UP TO 300 KG!



www.bahco.com




BAHCO QUICKCLAMPS
MADE FOR PRESSURE - UP TO 300 KG!

QCS SERIES

Superior™

The Superior range is made for very demanding work where high force tension, strength and durability is needed. Thanks to its Power Lever and the glass fiber enforced polyamide body, this clamp is perfect to use in rough environments, and will give you extra tough clamping. Clamping up to 300 mm.

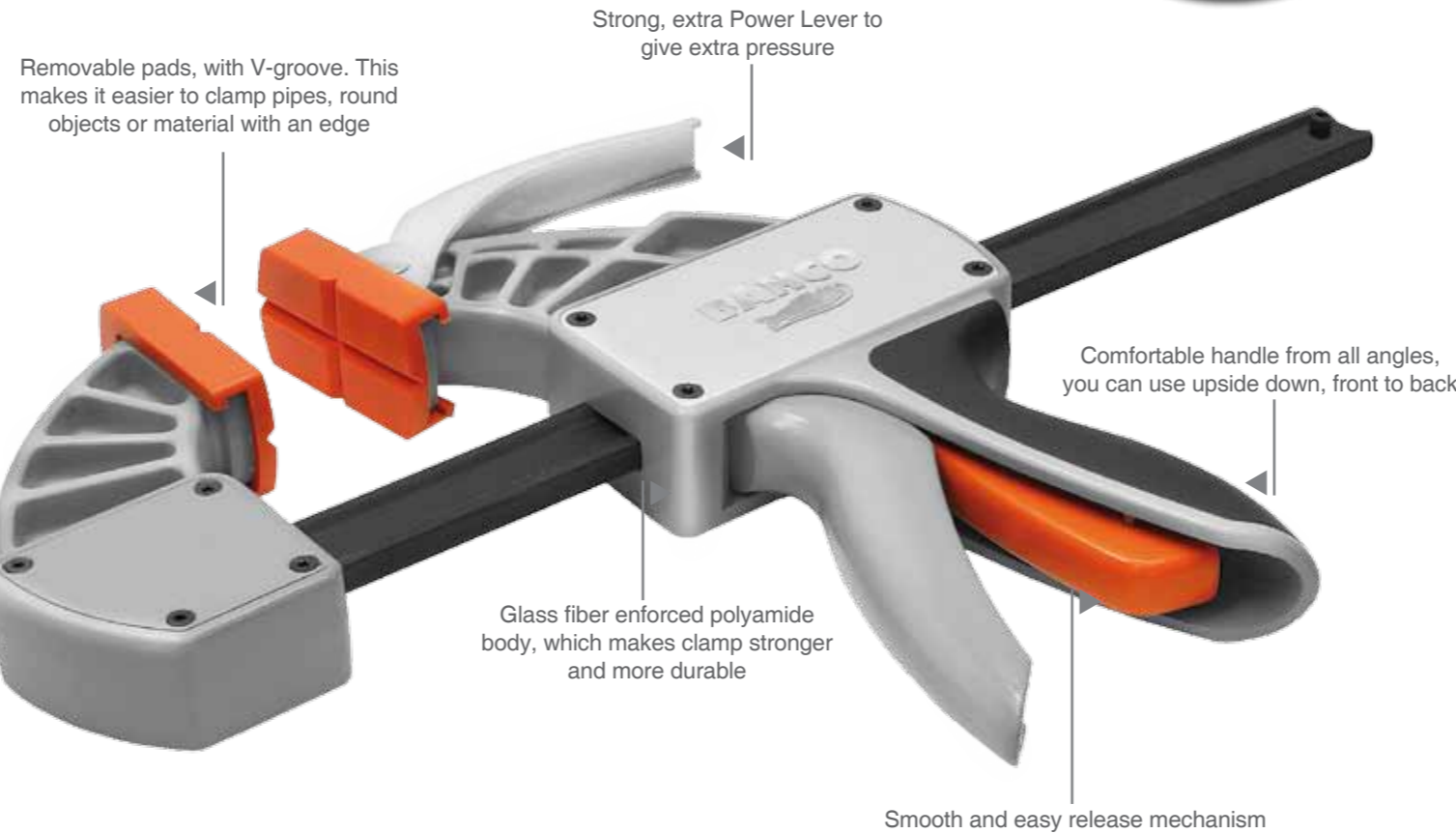

QCB SERIES

This clamp is made for the everyday professional work where strong clamping is needed. The variable speed clamping function, makes the high clamping force easier to reach as the clamp moves a shorter distance when reaching the work piece. The QCB series are also easy to turn into a spreader using the orange spreader button to move the small clamping jaw. Clamping up to 1250 mm.



QCG SERIES

A very good clamp, slightly smaller than the rest of the range. Developed for the everyday clamping. This clamp is strong enough for most daily professional needs. The QCG range is also easy to turn into a spreader using the orange spreader button to move the small clamping jaw. Clamping up to 300 mm.



SPECIAL FEATURES & BENEFITS



Quick change spreader jaw
Ability to clamp or spread



Variable Speed Trigger
Clamp moves until it reaches the workpiece where it slows then to exert pressure



Flat base
Makes clamp stand flat on table without support pads



Easy release button
Releases clamp easily, no force is needed



"V" Groove Pads
Makes gripping odd shapes, like pipes or corners easier



Medium and Soft Pads
Changeable pads for different usage, makes clamping secure and non marking. Spare pads are available



Power Lever
Only on Superior clamp, for high pressure clamping



"Get extra clamping power with the innovative Bahco Power Lever System"

Power Lever System

"The Superior in the range is made for very demanding work where high force tension, strength and durability is essential. The extra Power Lever will add extra force to your clamping when needed. Simply lift the lever before clamping, clamp as usual with handles, then press the lever down to get the extra kg of clamping pressure! If you do not need the extra force, simply leave lever down in resting position Easy and efficient high force clamping"

Inspiration

The crocodile is said to be the strongest reptile alive. They are believed to be over 200 million years and outlived the dinosaurs - they are one of the originals. They have a streamlined body which makes them move smoothly, they can clamp their jaws together with a force of over 1000 kilos. We got inspired of this amazing marine creature and decided to create the BAHCO RANGE OF CLAMPS, including our very own crocodile; the Superior with a clamping force of up to 300 kg!



*No animals were hurt during production of these images.