




COREX II

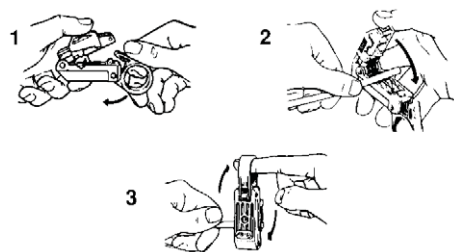

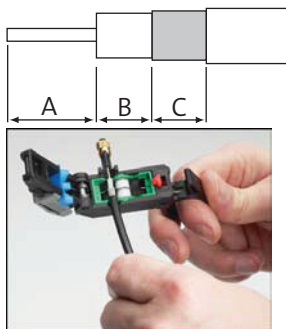

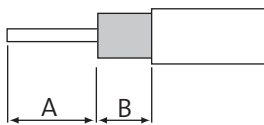

Complete stripping in 10 sec.


COREX II

Stripping tool for coaxial cable, diam 2.5-7.6 mm.

Corex II is always supplied with 1 basic tool, 1 cassette (will last up to 2000 strippings), 1 adjustment gauge, 4 V blocks, 1 adjusting spanner and Swedish instructions.









Order no.	Colour code	"A"	"B" mm	Weight g
CX-202		optional*	6.0	40
CX-203		optional*	9.2	40
CX-204		optional*	12.0	40
CX-207		optional*	6.8	40

*) can also be adjusted to size with C-ST.
The tool is supplied ready adjusted for RG58.

Order no.	Colour code	"A"	"B" mm	"C" mm	Weight g
CX-300		optional*	5.5	5.5	40
CX-301		optional*	2.7	8.3	40
CX-305		optional*	6.0	6.0	40
CX-309		optional*	2.5	6.8	40
CX-399		optional*	3.5	7.5	40

*) can also be adjusted to size with C-ST.

Knife cassette

Order no.	Colour code	Article	Mantle type
C-202		Knife cassette*	2 stage
C-203		Knife cassette*	2 stage
C-204		Knife cassette*	2 stage
C-207		Knife cassette*	2 stage
C-300		Knife cassette*	3 stage
C-301		Knife cassette*	3 stage
C-305		Knife cassette*	3 stage
C-309		Knife cassette*	3 stage
C-399		Knife cassette*	3 stage
C-ST	-	Cable clamp	
REDDY		Gauge for RG58/59 and RG 174/316	

*) see above table for relevant stripping length