


SOCKET STRIPS

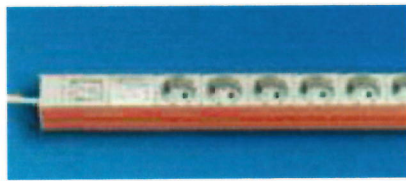

DOS00401

With switch



DOS00262

With switch



DOS20020

Without switch



DOS20021

With switch



DOS00263

Without switch

DI-STRIP® Compact Standard DIN 49 440

- Optionally with lit switch, 2-pole switching
- 19" installation option (with length 483 mm)
- 2 versions: Standard side panel or Design side panel
- Socket rotation: 45°
- Cable: H05VV-F 3G 1.5 mm²
- Moulded right angle plug
- Optionally with Euro plug, IEC320 for UPS applications

Material / Finish

Casing: closed sheet steel extrusion, zinc-plated, powder-coated texture
Plastic parts: Vampamid 6 0024 VO (UL94), recyclable
Internal conductor: full-length busbar, brass

Dimensions

Socket spacing: 50 mm
Height: 45.5 mm
Casing width: 44.4 mm (= 1 HU)
Cable: 2.5 m

Approvals

- CE Label in accordance with low voltage directive 2006/95/EEC
- EMC Directive 2006/108/EEC
- Innova-GS
- CB-scheme
- VDE

Colour combination

Final digit of order number .1:
RAL 7035 light-grey
Final digit of order number .6:
Casing, RAL 2003, pastel orange
Plastic parts: RAL 7035 light-grey

Load rating

100-240 Vac/16 A

Supply schedule

1 socket strip
2 mounting brackets
2 19" mounting brackets (additional with 19" installation option)

L	S	n	F1	F2	19"	Safe	Model	Order no.	UP
883		15	●					03.300.015.x	1 unit
732		11		●				03.300.111.x	1 unit
683		11	●					03.300.011.x	1 unit
532		7		●		●		03.301.107.x	1 unit
532		7		●				03.300.107.x	1 unit
483		7	●		●			03.300.007.x	1 unit
483		8	●		●			03.300.008.1	1 unit
382		4		●		●		03.301.104.x	1 unit
382		4		●				03.300.104.x	1 unit
333		4	●					03.300.004.x	1 unit
883	●	14	●				With switch	03.302.014.x	1 unit
732	●	10		●			With switch	03.302.110.x	1 unit
683	●	10	●				With switch	03.302.010.x	1 unit
532	●	6		●		●	With switch	03.303.106.x	1 unit
532	●	6		●			With switch	03.302.106.x	1 unit
483	●	6	●		●		With switch	03.302.006.x	1 unit
483	●	7	●		●		With switch	03.302.007.1	1 unit
382	●	3		●		●	With switch	03.303.103.x	1 unit
382	●	3		●			With switch	03.302.103.x	1 unit
333	●	3	●				With switch	03.302.003.x	1 unit

Dimensions in mm: L = Length, S = Switch, n = Number of sockets,
F1 = Standard side, F2 = Design side, 19" = Suitable for 19" installation, Safe =
Child-safe, HU = Standard height unit, UP = Unit of packaging

● = Express item

Conversion: 1 mm = 0.03937 inch 1 kg = 2.2046 pound

Replace .x with the number of the required colour combination:
.1 = RAL 7035, .6 = RAL 7035/RAL 2003