


Laserliner®

DigiLevel Laser 60 cm



Digital electronic spirit level:
Working exactly –
precise and user-friendly.

Rev 0109

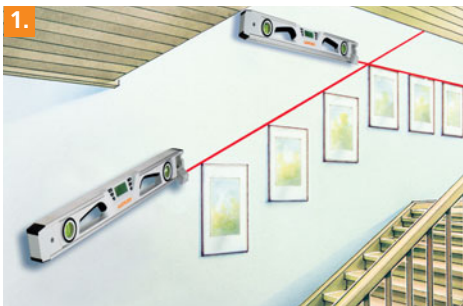

1. With wall-line-laser:

Optical extension of the measuring surface.



2. The intelligent spirit level:

The intelligent spirit level with vertical and horizontal angle display. The slope memory enables angles to be projected elsewhere. The separate measurement memory allows up to 9 measurement results to be retrieved and converted on the display into degrees, Inch/Feet or percent.



3. Optimal use by AutoSound:

Horizontal, vertical and 45° use with audible inclination guide. Easy levelling.

Additional features:

- The illuminated display is easy to read under all conditions - even during overhead measurements are involved.
- vertical and horizontal vial
- milled measuring surface
- strong magnets

TECHNICAL DATA

ELECTRONIC SLOPE measurement precision
 $\pm 0,1^\circ$ at 0° and 90° ,
 $\pm 0,2^\circ$ at $2^\circ - 89^\circ$

VIAL PRECISION $\pm 0,5$ mm/m

LASER class 2M

 
LASER WAVELENGTH 635 nm

POWER SUPPLY

Batteries 2 x 1,5 V type AAA

WEIGHT with batteries: 0,9 kg

DIMENSIONS (B x H x D)
72 x 33 x 640 mm



Article-No: 081.201A

EAN-Code: 4 021563 663156

DigiLevel Laser 60 cm

inclusive Softbag

+ batteries (2 x 1,5V type AAA)


Packing dimension (B x H x D)
195 x 810 x 195 mm

Transportpackaging dimension
VE 8

390 x 850 x 220 mm



Integrated wall-line-laser

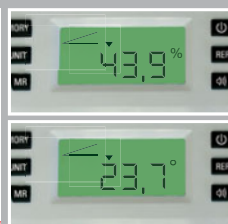

Illuminated display



Magnetic



AutoSound at $0^\circ/45^\circ/90^\circ/135^\circ/180^\circ$

OPTIMAL ADDITIONAL PRODUCT

ARTICLE	ARTICLENUMBER	EAN-CODE	VE
Laser Enhancement Glasses / for optimum visibility of the laser	020.70A	4 011879 643980	1