

ECA 11 E


Duct-mounted fan



Technical Data


Article	ECA 11 E
Air flow volume	105 m³/h
Rotating speed	2,500 1/min
Speed controllable	✓
Type of voltage	Alternating current
Rated voltage	230 V
Power frequency	50 Hz / 60 Hz
Power consumption	13 W
I _{Max}	0.1 A
Degree of protection (IP)	45
Mains cable	3 × 1.5 mm²
Type of installation	Recessed-mounted
Installation position	vertical, horizontal
Material	Synthetic material
Colour	Traffic white, similar to RAL 9016
Weight	0.725 kg
Nominal size	100 mm
Airstream temperature at I _{Max}	40 °C
Sound pressure level	37 dB(A)
Sortiment	A
EAN	4012799804604
Article number	0080.0460

Characteristic curve

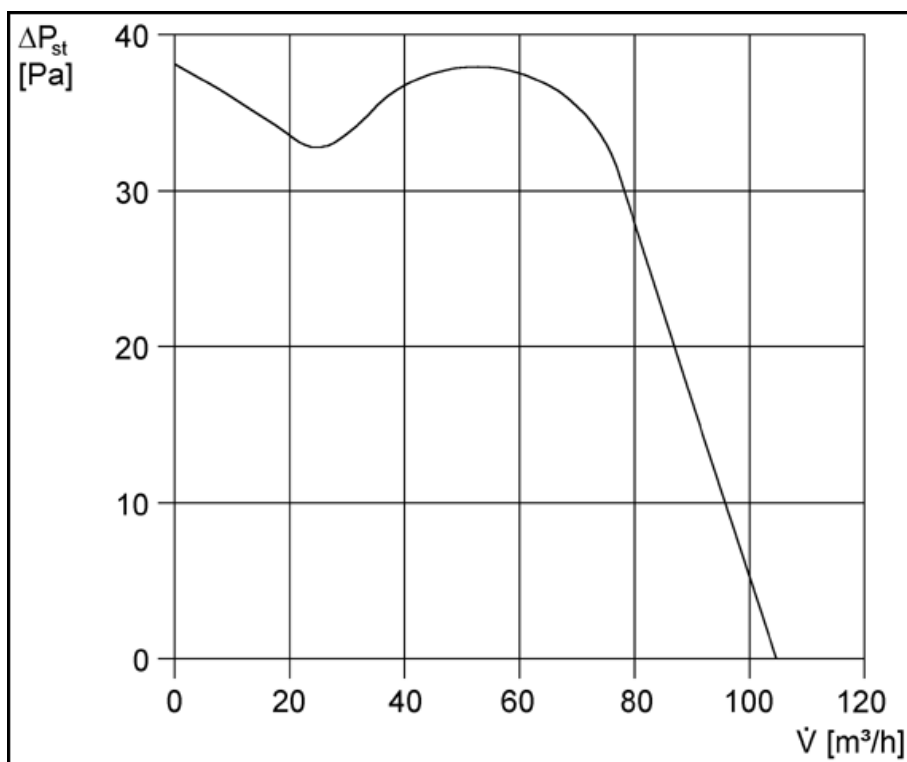

$V = 230 \text{ V}$
 $f = 50 \text{ Hz}$
 $n = 2500 \text{ min}^{-1}$

Dimensions [mm]

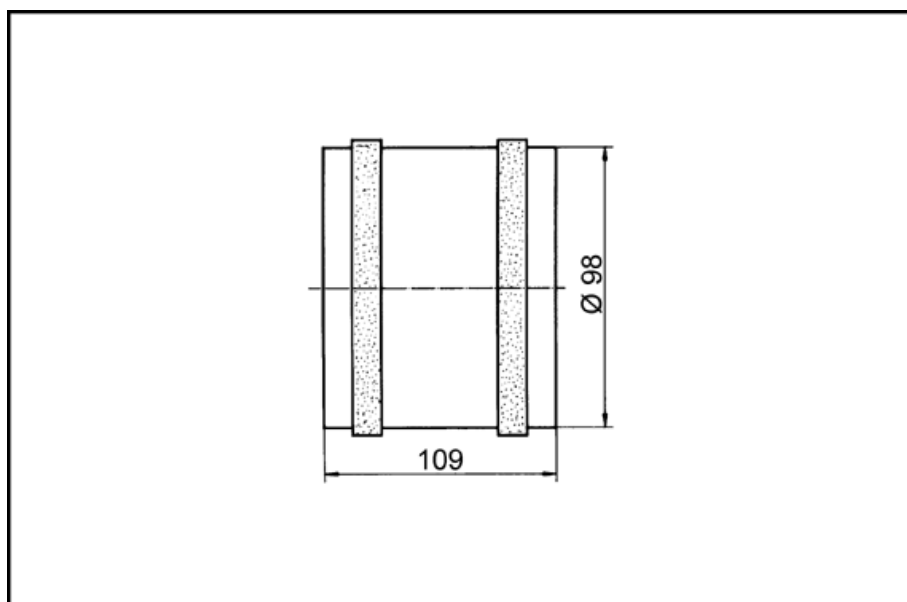

A	B
98	109