 



**KS4-19L**

Isolierter Ø 4 mm-Verbindungsstecker. Messingvollstecker, aus einem Stück gefertigt und mit federnden Kontaktlamellen.  
**Steckabstand: 19 mm.**

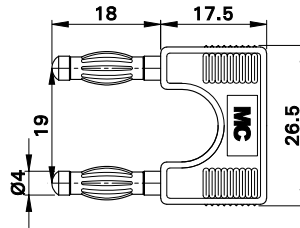



**KS4-19L**

Insulated Ø 4 mm connecting plug. Made of brass, one piece and with spring-loaded Multilams. **Plug spacing: 19 mm.**

Typ Type	Bestell-Nr. Order No.	Bemessungsspannung/-strom Rated voltage/current	Steckabstand Plug spacing		Farbe Colour
KS4-19L	24.0020-28	30 VAC ~ 60 VDC / 32 A	19 mm	Au	28

**KS4-19L/1**

 Isolierter Ø 4 mm-Verbindungsstecker aus Messing. Stecker mit federnden Kontaktlamellen. Mit isoliertem Griff und zwei axialen, starren Ø 4 mm-Buchsen, geeignet zur Aufnahme federnder Ø 4 mm-Stecker mit starrer Isolierhülse. **Steckabstand: 19 mm.**

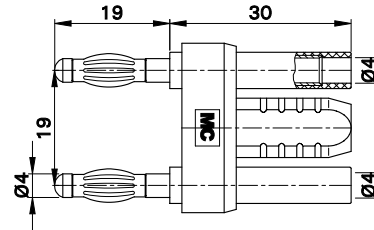

**KS4-19L/1**

Insulated Ø 4 mm connecting plug, made of brass. Plugs with spring-loaded Multilams. With insulated grip and with two in-line Ø 4 mm rigid sockets accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve. **Plug spacing: 19 mm.**

Typ Type	Bestell-Nr. Order No.	Bemessungsspannung/-strom Rated voltage/current	Steckabstand Plug spacing		Farbe Colour
KS4-19L/1	24.0027-21	30 VAC ~ 60 VDC / 32 A	19 mm	Ni	21