


MNX PC 125/60 HT

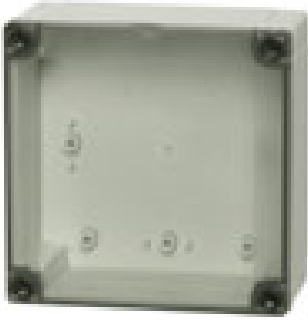

Sample photo

Order symbol: PC 125/60 HT
Product nbr: 6011907
Description: Enclosure, PC
Remarks: Smoked transparent cover

EAN: 6418074022349
EI. number:
 Finland: 3420441
 Denmark: 8212022399
 Italy: 7352055
 Sweden: 2535630
 Norway:

Including: Base with TPE gasket, screws for mounting plate/DIN-rail and cover with polyamide cover screws.

Dimensions:		Length	Width	Height	Rating:
mm:		130	130	60	Ingress Protection (EN 60529): IP 66/67
inch:		5.1	5.1	2.4	Impact Resistance (EN 62262): IK 08
Materials:					Electrical insulation: Totally insulated
Material:		Polycarbonate		Halogen free (DIN/VDE 0472, Part 815): Yes	
Base colour:		RAL 7035		UV resistance: UL 508	
Cover colour:		Smoked grey		Flammability Rating (UL 746 C 5): UL 746C 5V	
Cover screws material:		Polyamide		Glow Wire Test (IEC 695-2-1) °C: 960	
Cover screws colour:		Black		NEMA Class: NEMA 1, 4, 4X, 6	
Gasket material:		TPE			
Temperatures:					Certificates:
Short term:		-40 ... 120 °C		Germanischer Lloyd (GL)	
Continuous:		-40 ... 80 °C		Underwriters Laboratories	
Short term:		-40 ... 250 °F		Det Norske Veritas	
Continuous:		-40 ... 175 °F		Fimko	
Accessories:					Europe EN 62208: 2003
MIV 125		Mounting plate (Galvanized steel)		UL Canada	
MIN 10		DIN-15 Mounting rail		Gost R	
MIV 10		DIN-35 Mounting rail			
FP A 125/130		Front plate (Aluminium)			
HFP 130		Front plate hinge series			
FP 22046		Wall fastening lug (4 pcs)			

