



MultiMeter-Compact

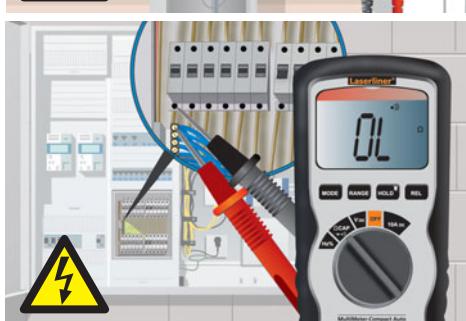

Compact universal multimeter with all functions for professionals

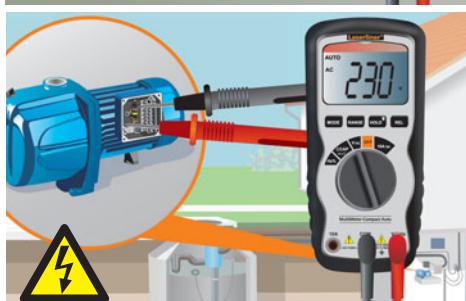

Large, illuminated display



Easy-to-use function knob



Vibration alarm

- Fast and precise **voltage, current, resistance, capacitance, frequency and duty factor measurement**
- Automatic range changeover and manual range preselection
- **Automatic continuity tester** with acoustic signal
- **Diode test function** for determining integrity and polarity
- **Integrated contactless voltage indicator** with acoustic, visual and vibration warning
- **High measurement resolution** for precisely determining different measurement variables
- **Data HOLD function** for measuring in inaccessible places
- **CAT III - 1000 V** – can be used for measurements throughout building installations
- Large, easy-to-read **LC display with back-lighting**
- Compact, impact-resistant enclosure with base support and selector switch

TECHNICAL DATA

MAX. INPUT VOLTAGE
1000 V AC/DC

VOLTAGE RANGE
V/DC: 0...600 V, ± 0.5%
V/AC: 0...600 V, ± 1.2%

CURRENT RANGE
A/DC: 0...10A, ± 2.5%
A/AC: 0...10A, ± 3.0%

RESISTANCE RANGE
0...20 Mohm, ± 0.8%

CAPACITANCE RANGE
0...100 µF, ± 3.0%

FREQUENCY RANGE
0...10MHz, ± 1.5%

DUTY FACTOR RANGE
0.1...99.9 %, ± 1.2%

CONTINUITY TEST
Resistance range <1.2 kohm

DIODE TEST
0.3 mA ±10%

PROTECTION CLASS II, double insulation

OVERVOLTAGE CATEGORY
CAT III - 1000 V / CAT IV - 600 V
Pollution degree 2

LC-DISPLAY 0...3999

POWER SUPPLY
1x 9V battery (NEDA 1604, IEC 6F22)

DIMENSIONS 150 x 70 x 48 mm

WEIGHT 255g



MultiMeter Compact

+ 2 test prods
+ batteries

Package size (W x H x D)
190 x 310 x 75 mm

ARTICLE	ARTICLE NO.	EAN CODE	PU
MultiMeter-Compact	083.034A	4 021563 671236	5