


Multilayer Capacitors, SMD



Capacitor 1210

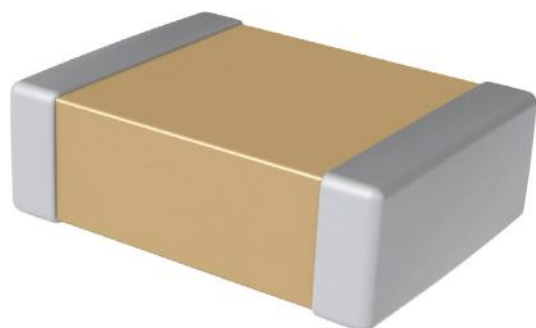

SPECIFICATION:

Construction form	1210
Ceramic type	X7R
Capacitance tolerance	±10%
Temperature range	-55...+125 °C
Length	3.2 mm
Width	2.5 mm

PRODUCT RANGE:

Art. Nr.	Capacitance	Rated voltage	Dimensions L x H x W	Height
RND1501210B152K102	1.5 nF	1000 VDC	3.2 x 1.25 x 2.5 mm	1.25 mm
RND1501210B222K102	2.2 nF	1000 VDC	3.2 x 1.25 x 2.5 mm	1.25 mm
RND1501210B103K501	10 nF	500 VDC	3.2 x 1.25 x 2.5 mm	1.25 mm
RND1501210B103K102	10 nF	1000 VDC	3.2 x 1.6 x 2.5 mm	1.6 mm
RND1501210B223K501	22 nF	500 VDC	3.2 x 1.25 x 2.5 mm	1.25 mm
RND1501210B473K201	47 nF	200 VDC	3.2 x 1.25 x 2.5 mm	1.25 mm
RND1501210B473K631	47 nF	630 VDC	3.2 x 1.6 x 2.5 mm	1.6 mm
RND1501210B104K500	100 nF	50 VDC	3.2 x 0.95 x 2.5 mm	0.95 mm
RND1501210B104K101	100 nF	100 VDC	3.2 x 0.95 x 2.5 mm	0.95 mm
RND1501210B104K201	100 nF	200 VDC	3.2 x 1.6 x 2.5 mm	1.6 mm
RND1501210B224K101	220 nF	100 VDC	3.2 x 1.25 x 2.5 mm	1.25 mm
RND1501210B224K201	220 nF	200 VDC	3.2 x 2.5 x 2.5 mm	2.5 mm
RND1501210B334K201	330 nF	200 VDC	3.2 x 2.5 x 2.5 mm	2.5 mm
RND1501210B474K500	470 nF	50 VDC	3.2 x 1.25 x 2.5 mm	1.25 mm
RND1501210B474K101	470 nF	100 VDC	3.2 x 2.5 x 2.5 mm	2.5 mm
RND1501210B474K201	470 nF	200 VDC	3.2 x 2.5 x 2.5 mm	2.5 mm
RND1501210B105K500	1 µF	50 VDC	3.2 x 1.25 x 2.5 mm	1.25 mm
RND1501210B105K101	1 µF	100 VDC	3.2 x 2 x 2.5 mm	2 mm
RND1501210B226K100	2.2 µF	10 VDC	3.2 x 2.5 x 2.5 mm	2.5 mm
RND1501210B475K500	4.7 µF	50 VDC	3.2 x 2.5 x 2.5 mm	2.5 mm
RND1501210B106K250	10 µF	25 VDC	3.2 x 2 x 2.5 mm	2 mm