


PCB Terminal Blocks

5 mm pitch, Low Profile

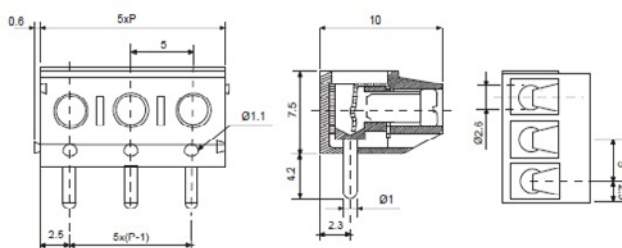

Low profile

2-3 pole interlocking

Test probe facility

Wire protector terminals

Guided pin alignment

Withstand Voltage - AC2000V/1min

Recommended PCB hole size - $\varnothing 1.2\text{mm}$

SPECIFICATION:

Pitch	5 mm
Termination type	Clamp Terminals/Screw Connection
Connection direction	90°
Rated current to EN	15 A
Rated current to UL	15 A
Rated voltage to EN	300 V
Rated voltage to UL	300 V
Connection cross-section	1.5 mm ²
Colour	black
Temperature range	-33...+120 °C
Width	10 mm
Height	7.6 mm
Material	UL 94V-0

PRODUCT RANGE:

Art. Nr.	Poles	Length
RND 205-00276	2	10 mm
RND 205-00277	3	15 mm
RND 205-00278	4	20 mm
RND 205-00279	5	25 mm
RND 205-00280	6	30 mm
RND 205-00281	7	35 mm
RND 205-00282	8	40 mm
RND 205-00283	9	45 mm
RND 205-00284	10	50 mm
RND 205-00285	11	55 mm
RND 205-00286	12	60 mm