

Slotted

Straight



Code	mm	mm	mm	mm		g
BE-8002	0.3	2.0	60	20x122	5	30
BE-8010	0.4	2.5	60	20x122	5	31
BE-8210	0.4	2.5	75	20x122	5	33
BE-8020	0.5	3.0	60	20x122	5	30
BE-8020L	0.5	3.0	75	20x122	5	33
BE-8022	0.5	3.0	100	20x122	5	34
BE-8220	0.5	3.0	125	20x122	5	36
BE-8225	0.5	3.0	200	20x122	5	45
BE-8030	0.6	3.5	75	20x122	5	34
BE-8235	0.6	3.5	200	20x122	5	45
BE-8230	0.6	3.5	125	20x122	5	37
BE-8040	0.8	4.0	100	20x122	5	39
BE-8240	0.8	4.0	175	20x122	5	47
BE-8242	1.0	5.5	150	27x122	5	47
BE-8250L	1.0	5.5	200	27x122	5	90
BE-8241	1.0	5.5	125	27x122	5	47
BE-8251	1.0	6.0	150	36x122	5	44
BE-8252	1.2	6.5	150	36x122	5	47

Flat




Code	mm	mm	mm	mm		g
BE-8150	1.0	5.5	100	27x122	5	66
BE-8250	1.0	5.5	150	27x122	5	112
BE-8155	1.2	6.5	125	36x122	5	73
BE-8255	1.2	6.5	150	36x122	5	116
BE-8256	1.6	8.0	150	36x122	5	135
BE-8257	1.6	8.0	175	36x122	5	140
BE-8258	1.6	10.0	200	36x165	5	195

Stubby



Code	mm	mm	mm	mm		g
	0.6	3.5	25	36x58	5	37
BE-8340	0.8	4.0	25	36x58	5	38
BE-8350	1.0	5.5	25	36x58	5	40
BE-8450	1.0	5.5	45	36x58	5	44
BE-8355	1.2	6.5	25	36x58	5	43
BE-8455	1.2	6.5	45	36x58	5	48
BE-8360	1.2	8.0	25	36x58	5	44

WHAT IS THE DIFFERENCE BETWEEN FLAT AND STRAIGHT?

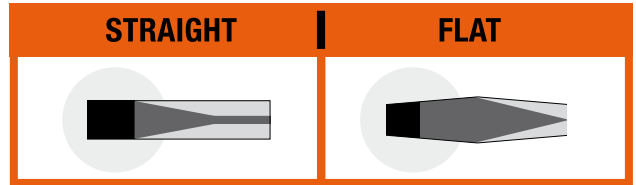

Hexagonal profile




Code	mm	mm	mm	mm		g
BE-8158	1.0	5.5	125	27x122	5	75
BE-8159	1.2	6.5	150	36x122	5	125
BE-8160	1.6	8	125	36x122	5	162
BE-8260	1.6	8	175	36x122	5	179

Hexagonal blade double handle



Code	mm	mm	mm	mm		g
BE-8865	1.6	8	175	36x165	5	209
BE-8870	1.6	10	175	36x165	5	210
BE-8880	2.0	12	200	36x165	5	291
BE-8890	2.5	14	200	36x165	5	293

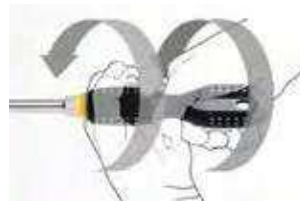

DOUBLE HANDLE

Double shape handle, for use with both hands (in large sizes). Its larger surface of elastomere together with its advanced ergonomic design allow an optimum comfortable grip and maximum torque power.