


STL1350/..-3.5-V-BLACK

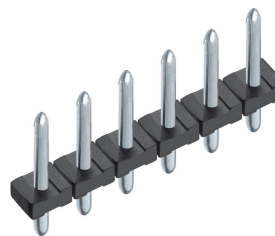

Technical Data

Wire Sizes	Insulating Material
Solid min -	Material PA 6.6
solid max -	Flammability Class UL 94 V-0
Stranded (flexible) -	Temperatures
min -	Operating Temperature -30 °C - 105 °C
Stranded (flexible) -	Wave Soldering Process
max -	Soldering Temperature, recommended 265 °C
Stranded with Ferrule -	Peak Soldering Time, recommended 3-4 s
min -	Reflow Process
Stranded with Ferrule -	Soldering Temperature, recommended -
max -	Peak Soldering Time, recommended -
Dimensions	
Stripped Length	
PCB Hole Diameter 1.3 mm	
Materials	
Contact Pin Brass	

Colours


	BLACK, RAL9011
	LIGHT GREY, RAL7035
	GREEN, RAL6018
	ORANGE, RAL2011
	RED, RAL3003
	BLUE, RAL5015
	YELLOW, RAL1018

Colours according to RAL, there may be variations on colour due to production conditions.
Special colours on request.

Counterparts (Spacing 3.5 mm)

Pin Strip/Terminal Blocks
AK1350

If there are combinations with different ratings, the lower value is valid.

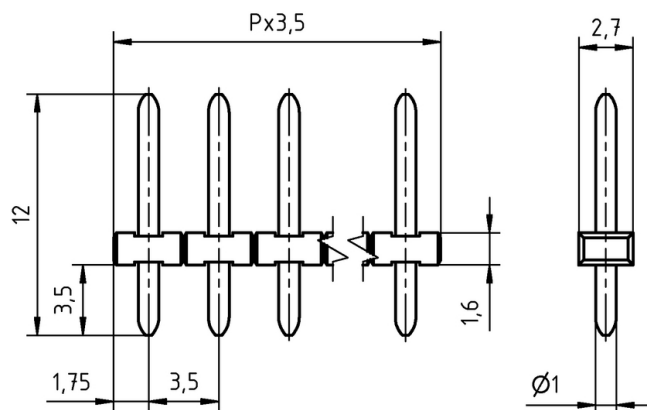

Order Data (Spacing 3.5 mm)

Poles	Width (mm)	Article Designation	Article Number	PU
2	7.00	STL1350/2-3.5-V-BLACK	51350025001G	250
3	10.50	STL1350/3-3.5-V-BLACK	51350035001G	250
4	14.00	STL1350/4-3.5-V-BLACK	51350045001G	250
5	17.50	STL1350/5-3.5-V-BLACK	51350055001G	250
6	21.00	STL1350/6-3.5-V-BLACK	51350065001G	250
7	24.50	STL1350/7-3.5-V-BLACK	51350075001G	250
8	28.00	STL1350/8-3.5-V-BLACK	51350085001E	100
9	31.50	STL1350/9-3.5-V-BLACK	51350095001E	100
10	35.00	STL1350/10-3.5-V-BLACK	51350105001E	100
11	38.50	STL1350/11-3.5-V-BLACK	51350115001E	100
12	42.00	STL1350/12-3.5-V-BLACK	51350125001E	100
13	45.50	STL1350/13-3.5-V-BLACK	51350135001D	50
14	49.00	STL1350/14-3.5-V-BLACK	51350145001D	50
15	52.50	STL1350/15-3.5-V-BLACK	51350155001D	50
16	56.00	STL1350/16-3.5-V-BLACK	51350165001D	50
17	59.50	STL1350/17-3.5-V-BLACK	51350175001D	50
18	63.00	STL1350/18-3.5-V-BLACK	51350185001D	50
19	66.50	STL1350/19-3.5-V-BLACK	51350195001D	50
20	70.00	STL1350/20-3.5-V-BLACK	51350205001D	50
21	73.50	STL1350/21-3.5-V-BLACK	51350215001D	50
22	77.00	STL1350/22-3.5-V-BLACK	51350225001D	50
23	80.50	STL1350/23-3.5-V-BLACK	51350235001D	50
24	84.00	STL1350/24-3.5-V-BLACK	51350245001D	50

Ratings



Usegroup	B	C	D	
Rated Voltage	150 V	-	-	125 V
Rated Current	9 A	-	-	8 A
Overvoltage Category				III
Test Voltage	1.3 kV	-	-	2.5 kV
Pollution Degree				3