

Universe	Sport
Type	Lighting
Category	ACTIVE headlamps
Subcategory	ACTIVE headlamps




hybrid
CONCEPT

ACTIK

The ACTIK headlamp offers 300 lumen brightness. Featuring a mixed beam, it is ideal for outdoor activities like mountaineering, running, hiking and backpacking. Red lighting preserves night vision and prevents blinding other members of the group. Its reflective headband helps you to be seen when a light is shone on it, and is equipped with an emergency whistle for rescue situations. ACTIK is a HYBRID headlamp that is also compatible with the CORE rechargeable battery.



Multi-beam headlamp designed for proximity lighting, movement, and distance vision. White and red lighting for nocturnal stealth.

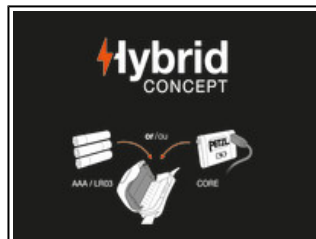

ACTIK is a HYBRID headlamp: it comes with three standard batteries, and is also compatible with the CORE rechargeable battery.



Adjustable elastic headband is equipped with an emergency whistle and retro-reflective markings to optimize visibility.

Short Description Compact multi-beam headlamp with red lighting, designed for outdoor activities. 300 lumens

- Selling Points**
- Powerful (300 lumens), versatile headlamp
 - Two beam patterns (wide or mixed) and several lighting modes meet the need for high-performance lighting in outdoor activities: proximity or distance vision and rapid movement
 - Long burn time:
 - Red lighting preserves night vision and keeps from blinding other members of the group
 - Reflective headband helps you to be seen when a light is shone on it, and is equipped with an emergency whistle for rescue situations
 - ACTIK is a HYBRID headlamp: it comes with three standard batteries, and is also compatible with the CORE rechargeable battery

-
- Specification**
- Light output: 300 lumens
 - Weight: 92g
 - Beam pattern: wide or mixed
 - Energy: Three AAA/LR03 batteries (included) or CORE rechargeable battery (available as accessory)
 - Battery compatibility: rechargeable Ni-MH or lithium
 - Certification(s): CE
 - Watertightness: IP X4 (weather resistant)
-

Lighting performance

Lighting color	Lighting modes	Brightness	Distance	Burn time
white	MAX AUTONOMY	5 lm	10 m	260 h
	STANDARD	100 lm	45 m	60 h
	MAX POWER	300 lm	90 m	
red	proximity	2 lm	5 m	100 h
	strobe	visible at 700 m for 400 h		

Specifications by reference

Reference(s)	E99AAA	E99AAB	E99AAC
			
Color(s)	black	green	blue
Made in	FR	FR	FR
Guarantee	5 years	5 years	5 years
Packing	1	1	1
Case quantity	50	50	50
EAN	3342540106659	3342540106642	3342540106635

Accessory(ies) CORE
KIT ADAPT
NOCTILIGHT