


## Prototyping Board SMD

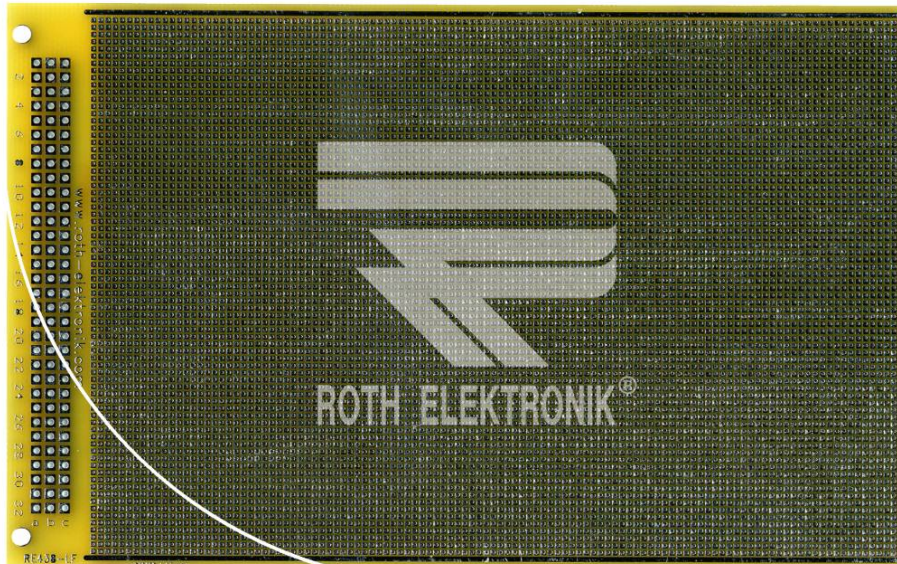

### RE438-LF

- EPOXY fibre-glass FR4 1.50 mm, double-sided 35 µm CU
- plated-through-holes
- HAL-leadfree
  
- hole spacing 1.27 x 1.27 mm
- 113 x 76 single-hole conductor 1.0 mm<sup>2</sup> (8588 pads)
- size 100 x 160 mm
- connector 32/ 64/ 96-channel
  
- DIN 41612 type C