


### SMT Labcard (1/40)

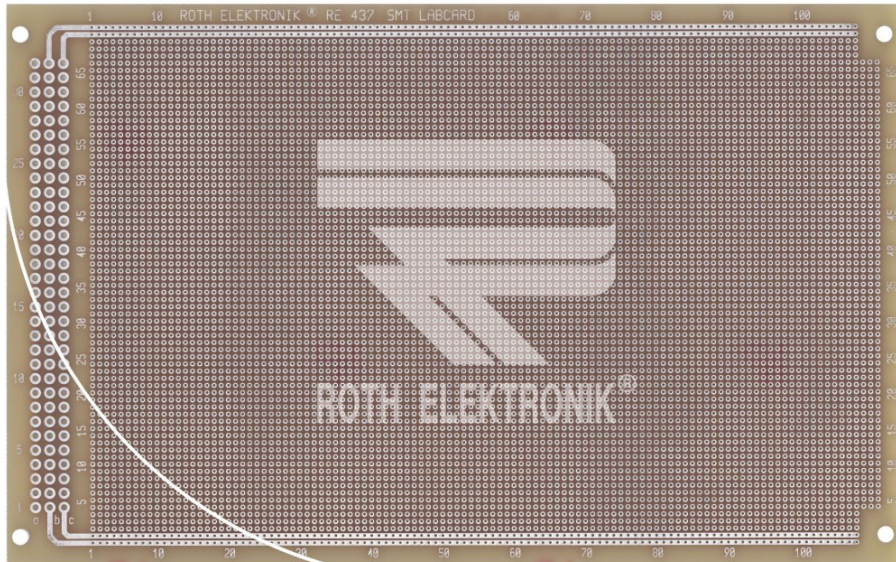

### RE437-LF

- EPOXY fibre-glass FR4 1.50 mm double-sided 35 µm CU (pth)
- chem. SN
- hole spacing 1.27 x 1.27 mm
- 108 x 69 single-hole conductor 1.0 mm<sup>2</sup>
- 4 potential strips
- connector 32/ 64/ 96-channel
- DIN 41612 type C
- size 100 x 160 mm