


E 14



BA 15d

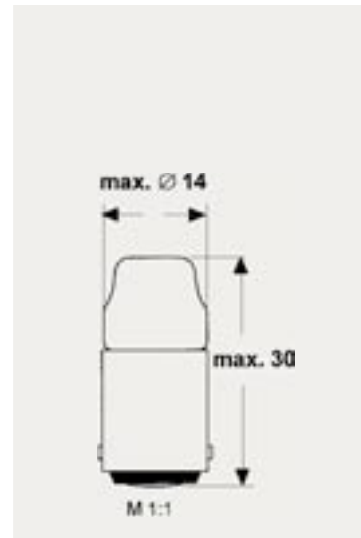

Spannung Voltage	Stromstärke Current	Leistung Power	Lichtstärke Light intensity	Lebensdauer Lifetime	Bestellcode Ordering Code	
					1430 40 ..	1430 50 ..
V	mA	Watt	MSCP	(h) AC		
6	830	5,00	3,900	1.000	1430 40 006 005	1430 50 006 005
6-7	330	2,00	0,600	5.000	1430 40 0607 02	1430 50 0607 02
12	250	3,00	1,500	2.500	1430 40 012 003	1430 50 012 003
12	417	5,00	2,500	2.000	1430 40 012 005	1430 50 012 005
12-15	165	2,00	0,600	5.000	1430 40 1215 02	1430 50 1215 02
24	80	2,00	0,800	8.000	1430 40 024 002	1430 50 024 002
24	125	3,00	1,200	2.000	1430 40 024 003	1430 50 024 003
24	208	5,00	1,800	1.500	1430 40 024 005	1430 50 024 005
24-30	80	2,00	0,800	5.000	1430 40 2430 02	1430 50 2430 02
30	65	2,00	0,800	8.000	1430 40 030 002	1430 50 030 002
30	100	3,00	1,000	5.000	1430 40 030 003	1430 50 030 003
30	166	5,00	1,800	1.500	1430 40 030 005	1430 50 030 005
36-45	55	2,00	0,800	5.000	1430 40 3645 02	1430 50 3645 02
48	63	3,00	1,000	3.000	1430 40 048 003	1430 50 048 003
48	105	5,00	1,500	2.000	1430 40 048 005	1430 50 048 005
48-60	42	2,00	0,500	6.000	1430 40 4860 02	1430 50 4860 02
60-70	35	2,00	0,400	6.000	1430 40 6070 02	1430 50 6070 02
220-260	23	5-7	0,500	2.000	1430 40 2226 57	1430 50 2226 57

Weitere Spannungen auf Anfrage. Further voltages on request.

Technische Änderungen vorbehalten. Technical changes reserved.