


LED Cluster BA15d
6 x 1 Chip AC/DC + AC

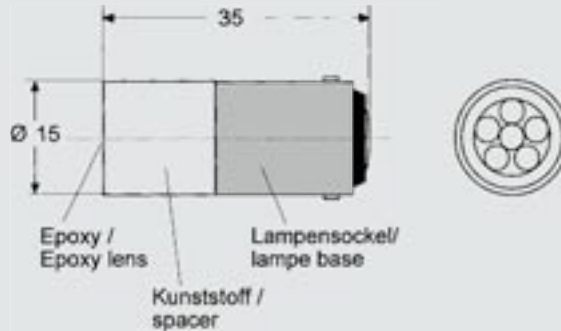

Spannung Voltage	Stromart Current type	Stromstärke Current	Farbe Colour	Wellenlänge Wavelength	Lichtstärke luminous intensity	LED-Chip	Bestellcode Ordering Code
V		mA		nm	mcd		
24	AC/DC	20	Rot/Red	630	900	6	166K 13 2420 ER
24	AC/DC	20	Gelb/Yellow	587	1000	6	166K 13 2420 EY
24	AC/DC	20	Grün/Green	525	14000	6	166K 13 2420 EG
24	AC/DC	20	Blau/Blue	470	5500	6	166K 13 2420 EB
24	AC/DC	20	Weiß/White	X=0,31 Y=0,32	9000	6	166K 13 2420 WS
28	AC/DC	20	Rot/Red	630	900	6	166K 13 2820 ER
28	AC/DC	20	Gelb/Yellow	587	1000	6	166K 13 2820 EY
28	AC/DC	20	Grün/Green	525	14000	6	166K 13 2820 EG
28	AC/DC	20	Blau/Blue	470	5500	6	166K 13 2820 EB
28	AC/DC	20	Weiß/White	X=0,31 Y=0,32	9000	6	166K 13 2820 WS
110-130	AC	9 - 11	Rot/Red	630	420-490	6	166K 13 1315 ER
110-130	AC	9 - 11	Gelb/Yellow	587	470-550	6	166K 13 1315 EY
110-130	AC	9 - 11	Grün/Green	525	6000-8000	6	166K 13 1315 EG
110-130	AC	9 - 11	Blau/Blue	470	2600-3000	6	166K 13 1315 EB
110-130	AC	9 - 11	Weiß/White	X=0,31 Y=0,32	4300-4900	6	166K 13 1315 WS
230	AC	17	Rot/Red	630	760	6	166K 13 2315 ER
230	AC	17	Gelb/Yellow	587	850	6	166K 13 2315 EY
230	AC	17	Grün/Green	525	12000	6	166K 13 2315 EG
230	AC	17	Blau/Blue	470	4600	6	166K 13 2315 EB
230	AC	17	Weiß/White	X=0,31 Y=0,32	7600	6	166K 13 2315 WS

Weitere Spannungen auf Anfrage.
Further voltages on request.

Technische Änderungen vorbehalten.
Technical changes reserved.