




Holder / No. 560

PC Mount, for TR5®/TE5® Fuses

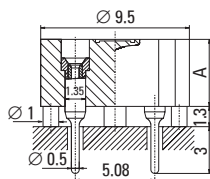

"A"	code	height
3.0 mm		13
4.3 mm		10

 Holes in PCB

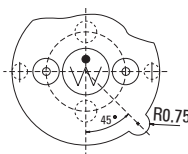

Specifications

Packaging

1	bulk (1000 pcs.)
0	bulk (500 pcs.)

Order Number

Holder	No. 560 0000 13 1
Holder	No. 560 0000 10 0
Holder	No. 560 0000 10 1

Mounting

PC Board, 5.08 mm pin spacing

Materials

Holder: Thermoplastic, UL 94 V-0
Polyester PCT
Metal parts: Copper alloy; solderable tinned

Electrical Data (23 °C)

Rated Voltage: 250 V
Max. Current/Power: 6.3 A/1.6 W

Soldering Heat Resistance

max. 280 °C, 10 s (Wave)

Minimum Cross Section

Conducting path - 0.1 mm²

Unit Weight

0.4 g




Order Information

Qty.	Order-Number	Series	code	height	Packaging
		560	0000		


Specifications are subject to change without notice

Holder / No. 559

PC Mount, for TR5®/TE5® Fuses leadfree

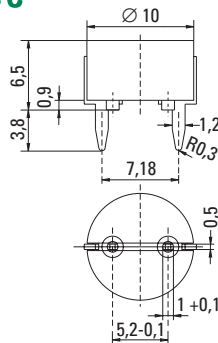

Holes in PCB

 

Packaging

000	bulk (1000 pcs.)
-----	------------------

Mounting

PC Board, 7.18 mm pin spacing

Materials

Holder: Black Thermoplastic, UL94 V-0
Polyamide PA 6.6
Metal parts: Copper alloy; solderable tinned

Electrical Data (23 °C)

Rated Voltage: 250 V
Max. Current/Power: 6.3 A/1.6 W

Solderability

max. 260 °C, 10 s (Wave)

Minimum Cross Section

Conducting path - 0.1 mm²

Unit Weight

0.63 g



Order Information

Qty.	Order-Number	Series	code	Packaging
		559	0000	000

Specifications are subject to change without notice

Note: 1.00 means the number one with two decimal places. 1,000 means the number one thousand.