




**T 6,8 k**  
**Telefonlampe**  
**6822**  
**6,8 x 22,0**

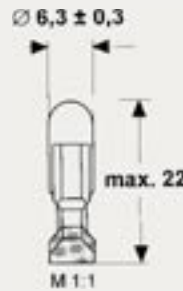

**T 6,8**  
**Telefonlampe**  
**6844**  
**6,8 x 44,0**  
 Sockel DIN 49601  
 DIN 49838 A

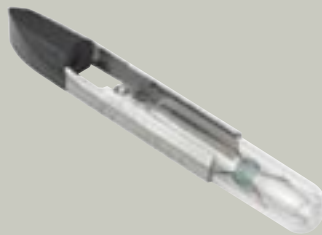

T 6,8 k

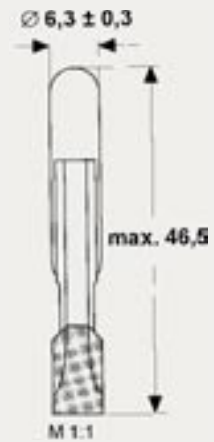


T 6,8

Spannung Voltage	Stromstärke Current	Leistung Power	Lichtstärke Light intensity	Lebensdauer Lifetime	Bestellcode Ordering Code	
					6822 00 ..	6844 00 ..
V	mA	Watt	MSCP	(h) AC	6822 00 ..	6844 00 ..
6	20	0,10	0,010	8.000	6822 00 006 020	6844 00 006 020
6	40	0,20	0,040	8.000	6822 00 006 040	6844 00 006 040
6	200	1,20	0,360	8.000		6844 00 006 200
12	20	0,20	0,020	8.000	6822 00 012 020	6844 00 012 020
12	40	0,50	0,090	6.000	6822 00 012 040	6844 00 012 040
12	50	0,60	0,130	6.000	6822 00 012 050	6844 00 012 050
12	100	1,20	0,290	6.000		6844 00 012 100
24	20	0,50	0,060	8.000	6822 00 024 020	6844 00 024 020
24	25	0,60	0,100	6.000	6822 00 024 025	6844 00 024 025
24	40	1,00	0,210	6.000	6822 00 024 040	6844 00 024 040
24	50	1,20	0,270	6.000	6822 00 024 050	6844 00 024 050
24	80	1,90	0,600	6.000		6844 00 024 080
24	100	2,40	0,800	6.000		6844 00 024 100
28	45	1,30	0,280	6.000	6822 00 028 045	6844 00 028 045
30	20	0,60	0,070	7.000	6822 00 030 020	6844 00 030 020
30	40	1,20	0,290	6.000	6822 00 030 040	6844 00 030 040
30	50	1,50	0,350	6.000		6844 00 030 050
30	80	2,40	0,710	6.000		6844 00 030 080

Weitere Spannungen auf Anfrage.  
 Further voltages on request.


Technische Änderungen vorbehalten.  
 Technical changes reserved.

**T 6,8 k**  
**Telefonlampe**  
**6822**  
**6,8 x 22,0**

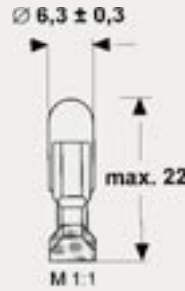

T 6,8 k

**T 6,8**  
**Telefonlampe**  
**6844**  
**6,8 x 44,0**  
 Sockel DIN 49601  
 DIN 49838 A

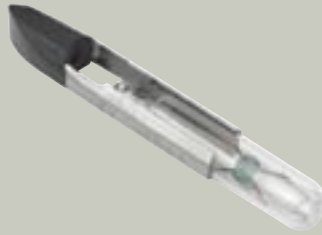

T 6,8

Spannung Voltage	Stromstärke Current	Leistung Power	Lichtstärke Light intensity	Lebensdauer Lifetime	Bestellcode Ordering Code	
					6822 00 ..	6844 00 ..
V	mA	Watt	MSCP	(h) AC	6822 00 ..	6844 00 ..
36	20	0,70	0,100	6.000	6822 00 036 020	6844 00 036 020
36	35	1,30	0,250	5.000		6844 00 036 035
36	40	1,40	0,270	6.000		6844 00 036 040
36	50	1,80	0,460	5.000		6844 00 036 050
48	20	1,00	0,140	6.000	6822 00 048 020	6844 00 048 020
48	25	1,20	0,210	5.000		6844 00 048 025
48	40	1,90	0,480	5.000	6822 00 048 040	6844 00 048 040
48	50	2,40	0,640	5.000	6822 00 048 050	6844 00 048 050
60	20	1,20	0,180	6.000	6822 00 060 020	6844 00 060 020
60	40	2,40	0,640	5.000		6844 00 060 040
60	50	3,00	0,800	5.000		6844 00 060 050
60	60	3,60	0,950	5.000		6844 00 060 060
70	20	1,40	0,210	5.000		6844 00 070 020
70	25	1,80	0,310	5.000		6844 00 070 025
70	30	2,10	0,450	5.000		6844 00 070 030
70	40	2,80	0,740	5.000		6844 00 070 040
80	20	1,60	0,240	5.000		6844 00 080 020
80	40	3,20	0,800	5.000		6844 00 080 040

Weitere Spannungen auf Anfrage.  
 Further voltages on request.

Technische Änderungen vorbehalten.  
 Technical changes reserved.