


m/m

CONTACT
POINT

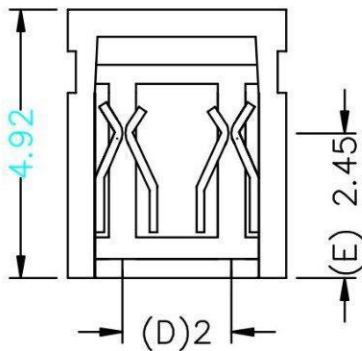

FEATURES

Double tuning fork type contact guarantees high reliability.
2.0MM pitch Low-Profile mini type Match to 0.50mm sq. posts.

MATERIAL

.Insulator.....P.B.T.(UL 94v-0)
.Contact.....Gold Plated
.Terminal.....5191 Phosphor Bronze

SPECIFICATIONS

.Current Rating: 3 amperes MAX
.Contact Resistance: 30m ΩMAX
.Insulation Resistance: 1000 megohms MAX
.Dielectric Withstanding Voltage: AC 650 volts RMS at sea level

* TOLERANCE:
INSULATOR: ±0.15
TERMINAL: ±0.05

RoHS Compliant		HSM 玄茂科技股份有限公司 HSUAN MAO TECHNOLOGY CO., LTD.	
APPD. 核准	SCALE 比例	TOLERANCE 容許公差	PART NAME 品名
DWG. 製圖	HELEN	.0 ± .00 ± ANG. ±	2.0mm MINI JUMPER 2P H:5.0mm CLOSE TYPE GOLD PLATING BLACK COLOR ROHS LOW-LEAD
DATE 制表日	UNIT 單位	SIZE 紙張尺寸	PART NO.
2010/2/12	MM	A4	C9700-02CBGB00R
	PAGE 張數	REV. 版次	料號
	1 OF 1	A	