


Greenline-Laser GL 1 Pro

New

Extrem visible laser for ground and wall applications.

This allows working on dark grounds and in very bright ambient light conditions.

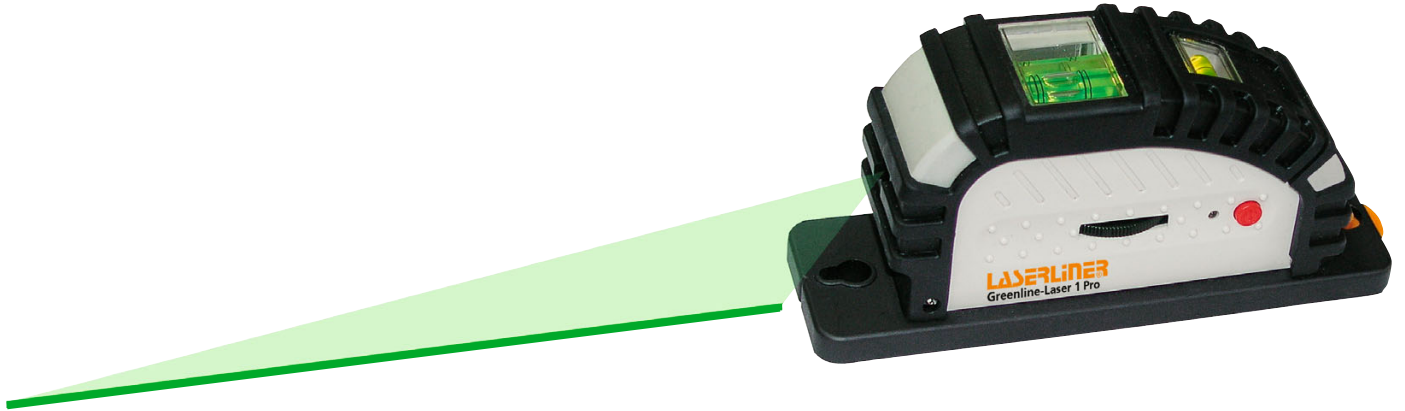

Professional Greenline-Laser, 522-542 nm, for ground applications as well as for horizontal and vertical levelling directly on the wall.

Depending on the ambient light conditions, therefore, green lasers are many times more visible than red ones – and indeed indoors, up to 12 times more than red lasers. This allows applications on dark grounds and over longer distances, as well as working in very bright ambient light conditions.

The length and intensity of the laser line can be adjusted. The laser is fixed to the wall using special pins and precisely aligned through the eccentric adjustment. Parallel shifts can be performed through the exact alignment of the laser line to the body edges. Additional magnets on the underside also allow the device to be mounted on steel structures. Precision: 5 mm / 10 m.

Incl.: High-performance rechargeable battery, mains unit / battery charger, laser enhancement glasses and carrying case.

Ordernumber 036.00.00A

UMAREX® GmbH & Co KG
Donnerfeld 2, D-59757 Arnsberg, Germany
Tel: +49 2932 638-300
Fax: +49 2932 638-333
www.laserliner.com

LASERLINER®
Innovation in Tools