

MeterMaster Pro Laser

36 meter
DOUBLE
DISTANCE
Calculation



Ultrasonic for measuring – Laser for focusing.



MeterMaster Pro Laser








Absolutely sure: Exact focusing of the target area through precise match between the laser circle and the ultrasonic measuring range.

Uniquely universal: Bigger range – 36 m and more – thanks to intelligent computation functions.

Incredibly versatile: The timer function and reference mode open up new possibilities, e.g. for measuring in inaccessible locations or the alignment of objects.

Surprisingly simple: Many direct buttons ensure uncomplicated handling. So both areas $x \cdot y$ (m²) and volumes $x \cdot y \cdot z$ (m³) can be calculated with astonishing ease and precision.

Exact measurement at any room temperature – climate-related changes in ultrasonic velocity are automatically corrected by the electronics. Measuring range 60 cm - 18 m, accuracy < 0,5 %. **Incl.:** 9 V battery.

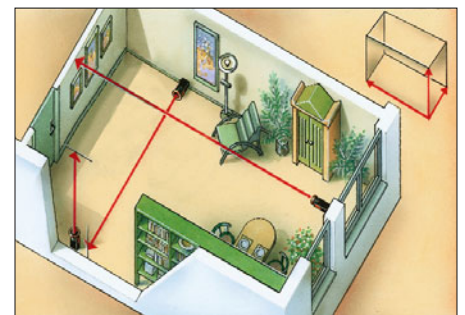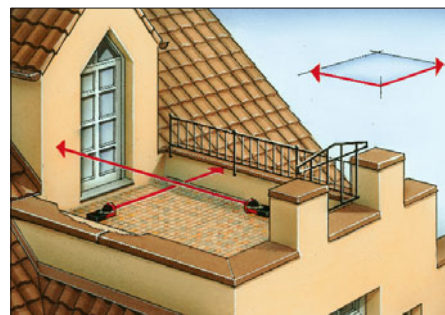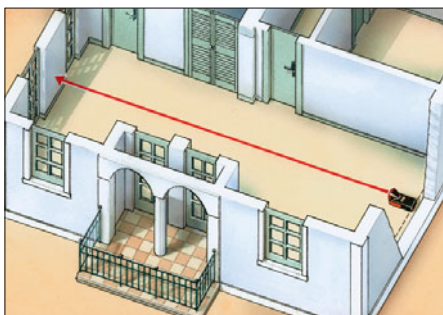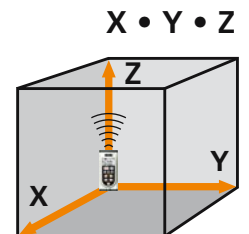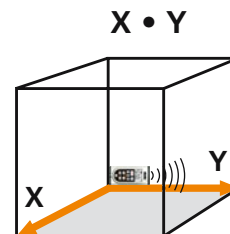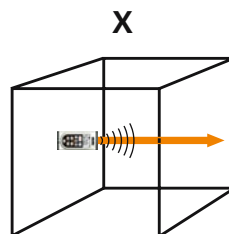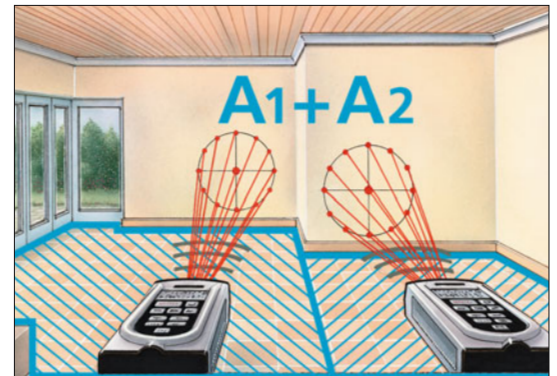

Ordernumber: 080.930A

UMAREX® GmbH & Co KG
Donnerfeld 2, 59757 Arnsberg, Germany
Tel: +49 2932 638-300
Fax: +49 2932 638-333
www.laserliner.com

LASERLINER®
Innovation in Tools