

Electric Sound type (Washable)

HMB series





HMB-06

HMB-12

Dip

Low current consumption

Characteristics

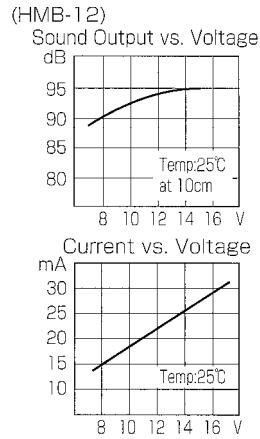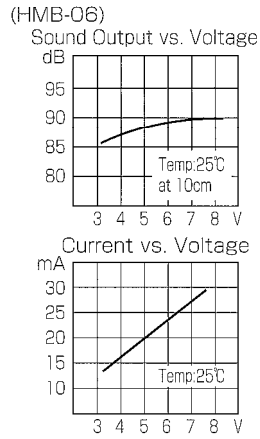

Specifications

Type	HMB-06	HMB-12
Rated Voltage (V)	6	12
Operating Voltage (V)	4~7	8~16
※ Mean Current Consumption (mA)	MAX30(TYP27)	MAX30(TYP25)
※ SPL at MIN 10cm (dBA)	MAX85(TYP90)	MAX85(TYP91)
※ Basic Frequency (Hz)	2,200±300	
☆ Response Time (msec)	MAX50	
Operating Temperature (°C)	-40~+85	
Storage Temperature (°C)	-40~+85	
Mass (g)	5	

※Value applying rated voltage ☆Value applying min. operating voltage

Dimensions [size : $\phi 16 \times 14.5\text{mm}$]

unit : mm / housing material : PPE-M (※)Longer pin is (+) polarity

