
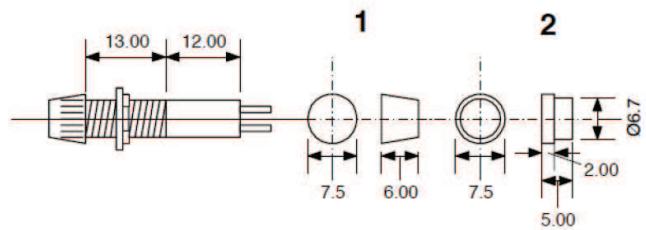


# Indicator lamp

## Indicators, 6.4 mm Panel Cutout

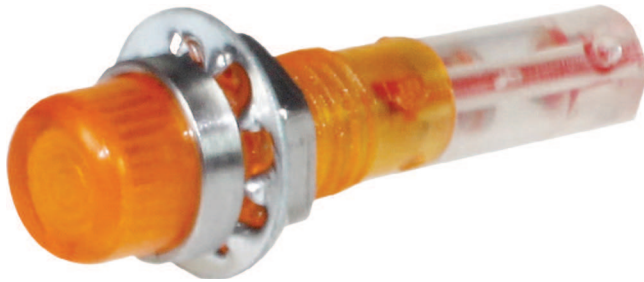

### FEATURES:

Trapezoid lens

For panel thicknesses 0.5-3.5mm

Supplied with nut and shakeproof washer

Stripped wire 164mm long

### SPECIFICATION:

Section	ø 6.5 mm
Termination type	Wires
Length	31 mm
Diameter	7.5 mm
Dimensions ø x L	7.5 x 31 mm

### PRODUCT RANGE:

Art. Nr.	Light Type	Voltage max.	Current	Colour
RND 210-00033	Incandescent	6 V	40 mA	amber
RND 210-00034	Incandescent	6 V	40 mA	green
RND 210-00035	Incandescent	6 V	40 mA	red
RND 210-00021	Incandescent	14 V	40 mA	amber
RND 210-00022	Incandescent	14 V	40 mA	green
RND 210-00023	Incandescent	14 V	40 mA	Opal
RND 210-00024	Incandescent	14 V	40 mA	red
RND 210-00029	Incandescent	28 V	30 mA	amber
RND 210-00030	Incandescent	28 V	30 mA	green
RND 210-00031	Incandescent	28 V	30 mA	Opal
RND 210-00032	Incandescent	28 V	30 mA	red
RND 210-00018	Neon	125 V	0.8 mA	amber
RND 210-00019	Neon	125 V	0.8 mA	green
RND 210-00020	Neon	125 V	0.8 mA	red
RND 210-00025	Neon	240 V	1 mA	amber
RND 210-00026	Neon	240 V	1 mA	green
RND 210-00027	Neon	240 V	1 mA	red
RND 210-00028	Neon	240 V	1 mA	clear