

ERR 10/1


Centrifugal duct fan, DN 100, single-phase AC



Technical Data

Article	ERR 10/1
Air flow volume	220 m³/h
Rotating speed	1,900 1/min
Speed controllable	✓
Type of voltage	Alternating current
Rated voltage	230 V
Power frequency	50 Hz
Nominal output	45 W
I_{nom}	0.2 A
I_{Max}	0.28 A
Degree of protection (IP)	X4
Insulation class	B
Installation position	vertical, horizontal
Housing material	Sheet steel, powder coated
Weight	3.8 kg
Nominal size	100 mm
Airstream temperature at nominal current	60 °C
Airstream temperature at I_{Max}	60 °C
Sortiment	C
EAN	4012799802709
Article number	0080.0270

Characteristic curve

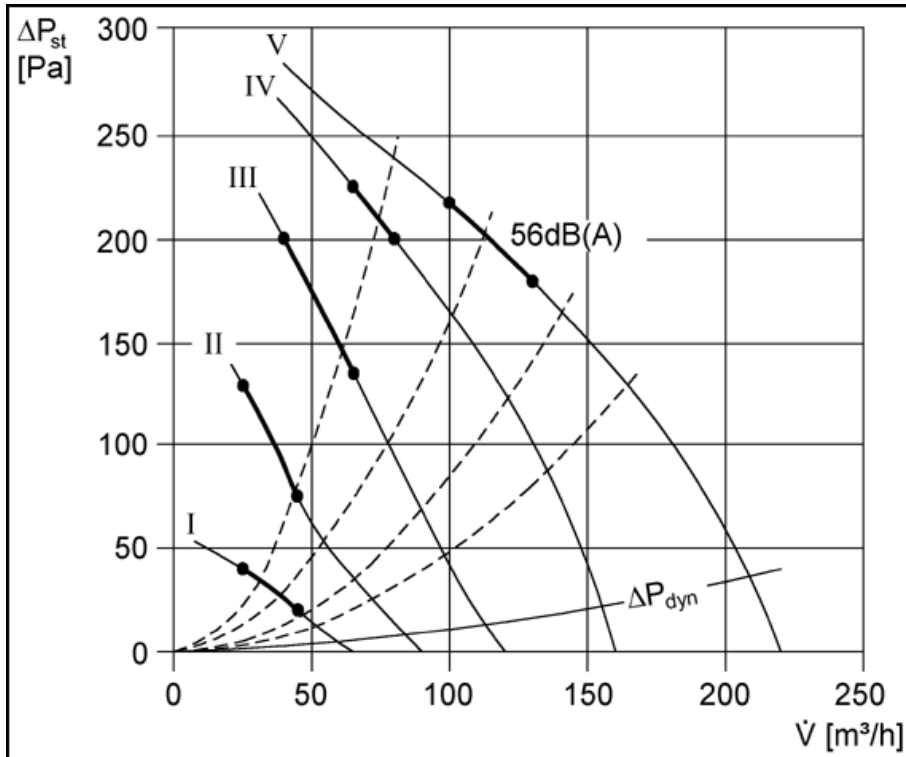

Dimensions [mm]

