



Subminiature Pushbutton Switches

Specifications:

Contact rating:	30 V DC, 650 mA
Contact resistance:	< 20 mΩ
Insulation resistance:	> 500 MΩ at 500 V DC
Dielectric strength:	500 V, 50 Hz for the duration of 1 minute
Mechanical life:	minimum 20 000 operations
Contacts:	brass, silver-plated
Terminals:	solder tags
Material:	phenolformaldehyde, black
Mounting:	single-hole
Soldering conditions:	hand-soldering – max.: 3 sec, 230° C ± 5° C


 
Models:

Contact arrangement

MSP 101 C

button colour: red



normally open

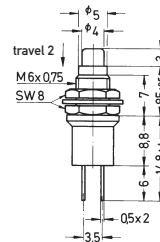

MSP 121 B

button colour: black
red


 
normally closed

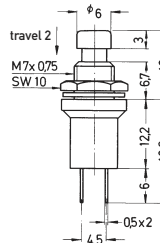

MSP 121 C

button colour: black
red

 normally open

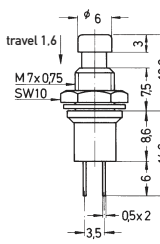

MSP 131 C

button colour: black

normally open

